



F4A-NMNR-1M5-P

FSJ4-50B SureFlex™ Jumper with interface types N Male and N Male Right Angle, 1.5 m


General Specifications

Body Style, Connector A	Straight
Body Style, Connector B	Right angle
Cable Family	FSJ4-50B
Interface, Connector A	N Male
Interface, Connector B	N Male
Length	1.500 m 4.921 ft
Variable Length	For custom lengths contact 1-800-255-1479 (North America), 1-779-435-6500 (International), or an Andrew representative

Electrical Specifications

3rd Order IMD	-116.00 dBm
DTF, Connector A	-34.00 dB
DTF, Connector B	-34.00 dB

Jumper Assembly Sample Label

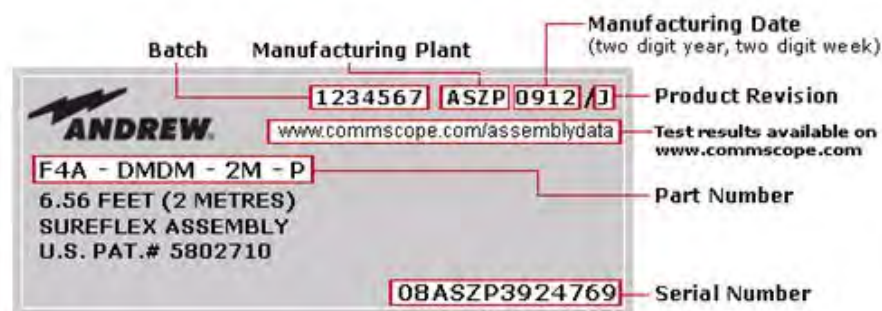

Return Loss/VSWR


Frequency Band	VSWR	Return Loss (dB)
698-960 MHz	1.08	28.00
698-960 MHz	1.10	26.40
1700-2200 MHz	1.08	28.00
1700-2200 MHz	1.10	26.40

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2008	Designed, manufactured and/or distributed under this quality management system

Included Products

 F4A-NMNR-1M5-P



FSJ4-50B — FSJ4-50B, HELIAX® Superflexible Foam Coaxial Cable, corrugated copper, 1/2 in, black PE jacket