



## F4A-PDMDM-1M5-S4

**FSJ4-50B SureFlex™ Jumper with interface types 7-16 DIN Male and 7-16 DIN Male, 1.5 m**


### General Specifications

Body Style, Connector A	Straight
Body Style, Connector B	Straight
Cable Family	FSJ4-50B
Interface, Connector A	7-16 DIN Male
Interface, Connector B	7-16 DIN Male
Length	1.500 m   4.921 ft

### Electrical Specifications

3rd Order IMD	-107.00 dBm
DTF, Connector A	-32.00 dB
DTF, Connector B	-32.00 dB

### Jumper Assembly Sample Label

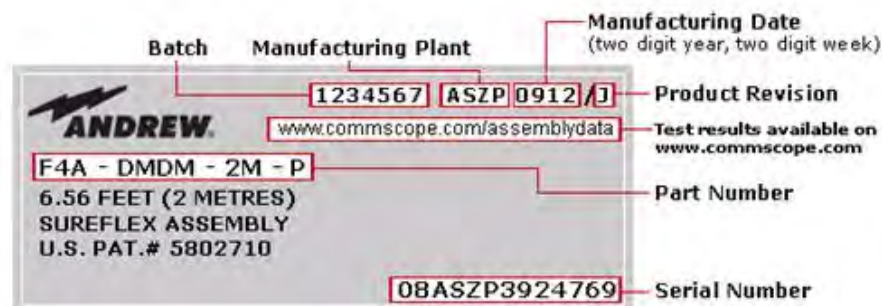

### Return Loss/VSWR

Frequency Band	VSWR	Return Loss (dB)
450–2000 MHz	1.11	26.00

### Regulatory Compliance/Certifications

 
Agency	Classification
RoHS 2002/95/EC	Compliant by Exemption
China RoHS SJ/T 11364-2006	Above Maximum Concentration Value (MCV)
ISO 9001:2008	Designed, manufactured and/or distributed under this quality management system



# Product Specifications

COMMScope®

F4A-PDMDM-1M5-S4



## Included Products

---

FSJ4-50B — FSJ4-50B, HELIAX® Superflexible Foam Coaxial Cable, corrugated copper, 1/2 in, black PE jacket