



F4A-TDMDR-10M-SHT

FSJ4-50B SureFlex™ Jumper with interface types 7-16 DIN Male and 7-16 DIN Male Right Angle, 10 m


General Specifications

Body Style, Connector A	Straight
Body Style, Connector B	Right angle
Cable Family	FSJ4-50B
Interface, Connector A	7-16 DIN Male
Interface, Connector B	7-16 DIN Male
Length	10.000 m 32.808 ft

Electrical Specifications

3rd Order IMD	-112.00 dBm
---------------	-------------

Jumper Assembly Sample Label

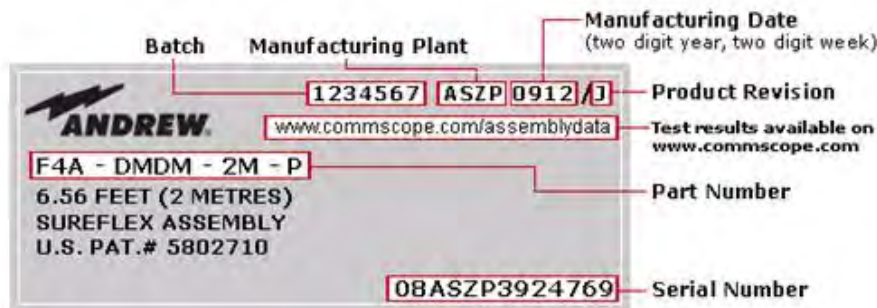

Return Loss/VSWR

Frequency Band	VSWR	Return Loss (dB)
300-2200 MHz	1.15	23.13

Regulatory Compliance/Certifications

Agency	Classification
RoHS 2002/95/EC	Compliant by Exemption
China RoHS SJ/T 11364-2006	Above Maximum Concentration Value (MCV)

 


Included Products

Product Specifications

COMMSCOPE®

F4A-TDMDR-10M-SHT



FSJ4-50B — FSJ4-50B, HELIAX® Superflexible Foam Coaxial Cable, corrugated copper, 1/2 in, black PE jacket