

## F4P43A-PNMNM-15M-X

FSJ4-50B SureFlex™ Jumper with interface types N Male and N Male, 15 m


### General Specifications

Body Style, Connector A	Straight
Body Style, Connector B	Straight
Cable Family	FSJ4-50B
Interface, Connector A	N Male
Interface, Connector B	N Male
Length	15.000 m   49.213 ft
Attachment, Connector B	Field attachment

### Electrical Specifications

DTF, Connector A	-32.00 dB
------------------	-----------

### Jumper Assembly Sample Label

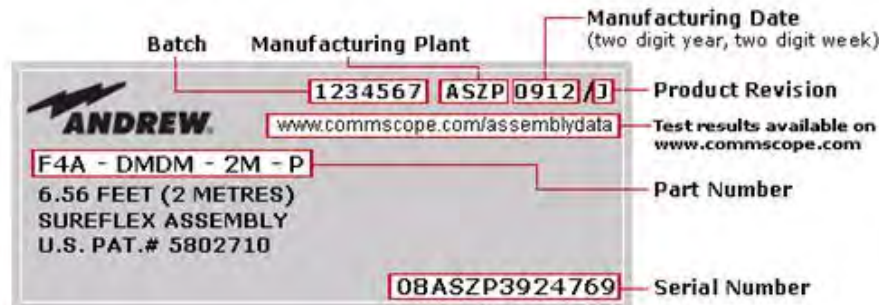

### Return Loss/VSWR

Frequency Band	VSWR	Return Loss (dB)
800–970 MHz	1.15	23.13
1420–1530 MHz	1.15	23.13
1700–2180 MHz	1.15	23.13

### Regulatory Compliance/Certifications

 
Agency	Classification
RoHS 2002/95/EC	Compliant by Exemption
China RoHS SJ/T 11364-2006	Above Maximum Concentration Value (MCV)
ISO 9001:2008	Designed, manufactured and/or distributed under this quality management system



# Product Specifications

COMMScope®

F4P43A-PNMNM-1.5M-X



## Included Products

---

FSJ4-50B — FSJ4-50B, HELIAX® Superflexible Foam Coaxial Cable, corrugated copper, 1/2 in, black PE jacket