



F4R-DMDM-P

FSJ4RK-50B SureFlex™ Jumper with interface types 7-16 DIN Male and 7-16 DIN Male, variable length


General Specifications

Body Style, Connector A	Straight
Body Style, Connector B	Straight
Cable Family	FSJ4-50B
Interface, Connector A	7-16 DIN Male
Interface, Connector B	7-16 DIN Male
Variable Length	For custom lengths contact 1-800-255-1479 (North America), 1-779-435-6500 (International), or an Andrew representative

Electrical Specifications

3rd Order IMD	-116.00 dBm
DTF, Connector A	-34.00 dB
DTF, Connector B	-34.00 dB

Jumper Assembly Sample Label

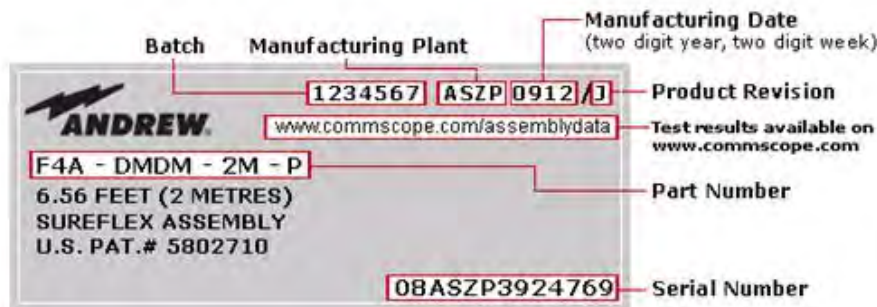

Return Loss/VSWR

Frequency Band	VSWR	Return Loss (dB)
698-960 MHz	1.06	30.00
698-960 MHz	1.10	26.40
1700-2200 MHz	1.06	30.00
1700-2200 MHz	1.10	26.40

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2008	Designed, manufactured and/or distributed under this quality management system

 
Included Products

FSJ4RK-50B — FSJ4-50B, HELIAX® Superflexible Foam Coaxial Cable, corrugated copper, 1/2 in, black non-halogenated,

Product Specifications

COMMScope®

F4R-DMDM-P



fire retardant polyolefin jacket