



F4R-NMDF-P

FSJ4RK-50B SureFlex™ Jumper with interface types N Male and 7-16 DIN Female, variable length


General Specifications

| | |
|-------------------------|--|
| Body Style, Connector A | Straight |
| Body Style, Connector B | Straight |
| Cable Family | FSJ4-50B |
| Interface, Connector A | N Male |
| Interface, Connector B | 7-16 DIN Female |
| Variable Length | For custom lengths contact 1-800-255-1479 (North America), 1-779-435-6500 (International), or an Andrew representative |

Electrical Specifications

| | |
|------------------|-------------|
| 3rd Order IMD | -116.00 dBm |
| DTF, Connector A | -34.00 dB |
| DTF, Connector B | -34.00 dB |

Jumper Assembly Sample Label

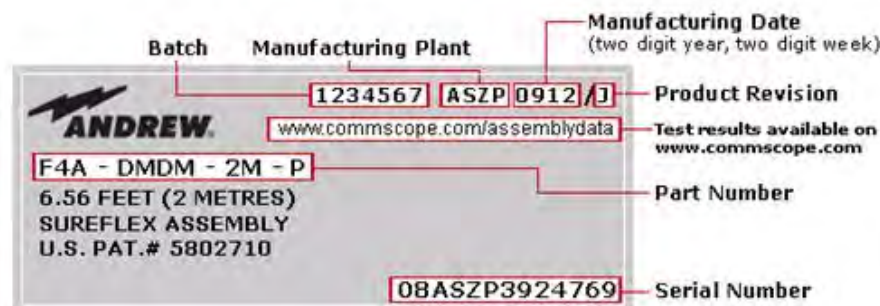

Return Loss/VSWR

| Frequency Band | VSWR | Return Loss (dB) |
|----------------|------|------------------|
| 698-960 MHz | 1.06 | 30.00 |
| 698-960 MHz | 1.10 | 26.40 |
| 1700-2200 MHz | 1.06 | 30.00 |
| 1700-2200 MHz | 1.10 | 26.40 |

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--|
| ISO 9001:2008 | Designed, manufactured and/or distributed under this quality management system |

 
Included Products

FSJ4RK-50B — FSJ4-50B, HELIAX® Superflexible Foam Coaxial Cable, corrugated copper, 1/2 in, black non-halogenated,

Product Specifications

COMMScope®

F4R-NMDF-P



fire retardant polyolefin jacket