

L4A-XDMDM-1M5

LDF4-50A SureFlex™ Jumper with interface types 7-16 DIN Male and 7-16 DIN Male, 1.5 m


General Specifications

Body Style, Connector A	Straight
Body Style, Connector B	Straight
Cable Family	LDF4-50A
Interface, Connector A	7-16 DIN Male
Interface, Connector B	7-16 DIN Male
Length	1.500 m 4.921 ft

Electrical Specifications

3rd Order IMD	-116.00 dBm
---------------	-------------

Jumper Assembly Sample Label

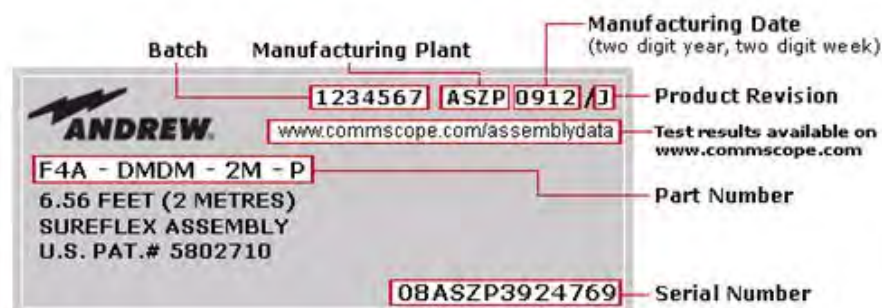

Return Loss/VSWR


Frequency Band	VSWR	Return Loss (dB)
806-960 MHz	1.05	32.00
1700-2170 MHz	1.06	30.00

Regulatory Compliance/Certifications

Agency	Classification
RoHS 2002/95/EC	Compliant by Exemption
China RoHS SJ/T 11364-2006	Above Maximum Concentration Value (MCV)
ISO 9001:2008	Designed, manufactured and/or distributed under this quality management system



 L4A:XDMDM-1M5



Included Products

LDF4-50A — LDF4-50A, HELIAX® Low Density Foam Coaxial Cable, corrugated copper, 1/2 in, black PE jacket

LDF4-50A-E1 — LDF4-50A-E1, HELIAX® Low Density Foam Coaxial Cable, corrugated copper, 1/2 in, black PE jacket