



L4P43A-PDF-3M

LDF4-50A SureFlex™ Jumper with interface type 7-16 DIN Female, 3 m


General Specifications

Body Style, Connector A	Straight
Cable Family	LDF4-50A
Interface, Connector A	7-16 DIN Female
Interface, Connector B	Sold separately
Length	3.000 m 9.843 ft

Electrical Specifications

DTF, Connector A	-32.00 dB
DTF, Connector B	-32.00 dB

Jumper Assembly Sample Label

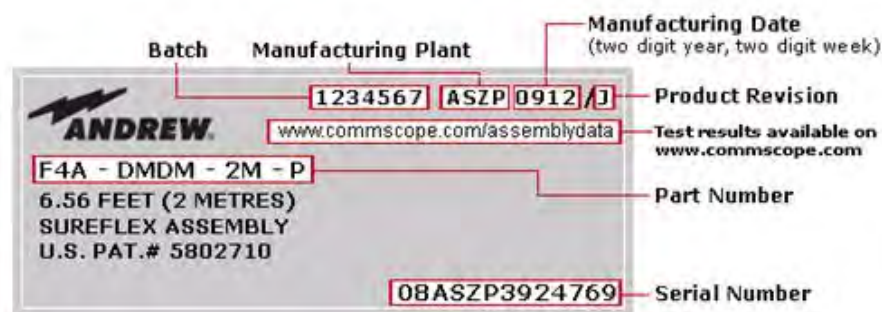

Return Loss/VSWR

Frequency Band	VSWR	Return Loss (dB)
800-970 MHz	1.15	23.13
1420-1530 MHz	1.15	23.13
1700-2180 MHz	1.15	23.13

Regulatory Compliance/Certifications

Agency	Classification
RoHS 2002/95/EC	Compliant by Exemption
China RoHS SJ/T 11364-2006	Above Maximum Concentration Value (MCV)
ISO 9001:2008	Designed, manufactured and/or distributed under this quality management system



Included Products

LDF4-50A — LDF4-50A, HELIAX® Low Density Foam Coaxial Cable, corrugated copper, 1/2 in, black PE jacket

LDF4-50A-E1 — LDF4-50A-E1, HELIAX® Low Density Foam Coaxial Cable, corrugated copper, 1/2 in, black PE jacket