



D137THSG
90° Rigid Twist for WR137, 5.85–8.2 GHz, with interface types UER70 and PDR70, 12 in, gray


Electrical Specifications

Operating Frequency Band 5.85 – 8.2 GHz
VSWR 1.06


General Specifications

Component	90° Rigid Twist
Waveguide Size	WR137 WG14 R70
Finish	Gray
Interface	UER70
Interface 2	PDR70
Length	305 mm 12 in


Component

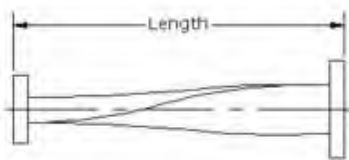

Interface

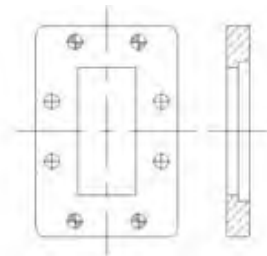

Interface 2

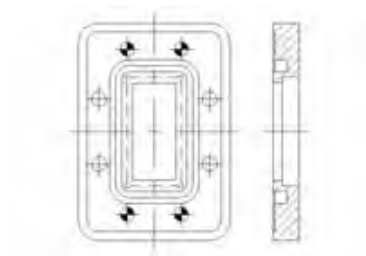

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2008	Designed, manufactured and/or distributed under this quality management system