

MC-RM1030-4  
Universal Ring Mount, 10 in to 30 in OD

## Dimensions

Mounting Diameter, maximum	762.0 mm		30 in
Mounting Diameter, minimum	254.0 mm		10 in
Height	254.0 mm		10.0 in
Length	152.4 mm		6.0 in
Mounting Circumference, maximum	2392.7 mm		94.2 in
Mounting Circumference, minimum	797.6 mm		31.4 in
Weight	140.7 kg		310.1 lb
Width	457.2 mm		18.0 in

## Environmental Specifications

Wind Rating	140 mph (BWS) at 150 ft AGL   160 mph (3-second gust) at 150 ft AGL using Exposure D per FBC
Wind Rating Criteria	Four 72 in x 8 in panel antennas per sector
Wind Rating Test Method	TIA/EIA-222

## General Specifications


Product Type	Universal ring mount
Includes	Mount   Threaded rod
Material Type	Hot dip galvanized steel
Mounting	Monopole, 254–762 mm (10–30 in) OD
Package Quantity	1
Sectors, quantity	4

MC-RM1030-4

POWERED BY



## Outline Drawing

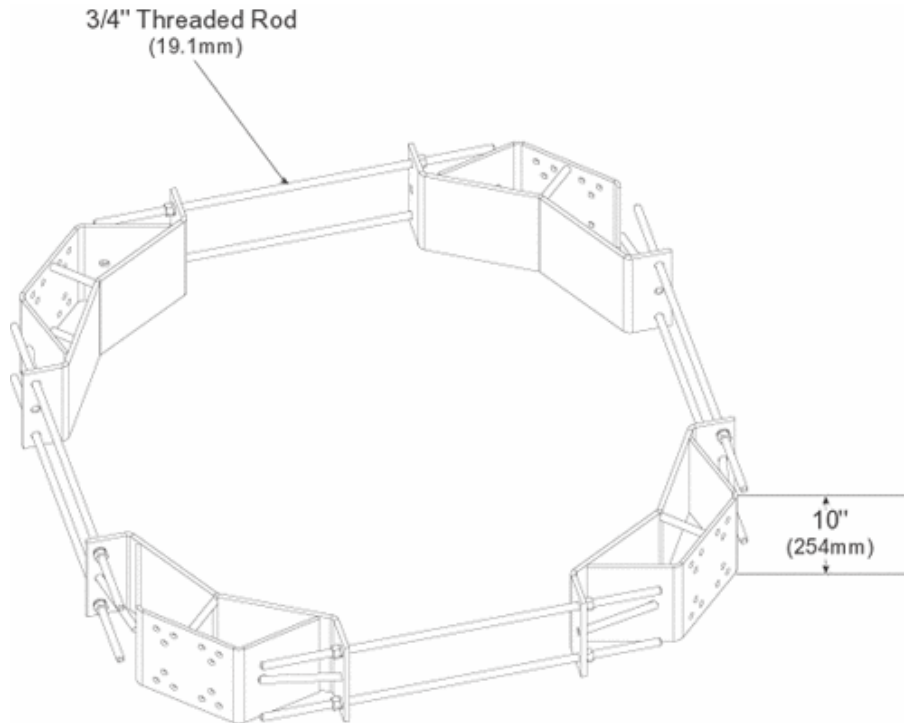

## Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2008	Designed, manufactured and/or distributed under this quality management system

### \* Footnotes

Wind Rating	BWS—Base Wind Speed; FBC—Florida Building Code
-------------	--