

MT-F1542-11
Rooftop Coaxial Cable Bridge Kit, for four coaxial cable runs, 12-gauge cover

Dimensions

Height	177.8 mm 7.0 in
Length	2.4 m 8.0 ft
Width	508.0 mm 20.0 in
Pipe Outer Diameter	60.3 mm 2 3/8 in
Weight	34.8 kg 76.6 lb

Environmental Specifications

Wind Rating	For specifications—contact 1-800-255-1479 (North America), 1-779-435-6500 (International), or a CommScope representative
-------------	--


General Specifications

Product Type	Coaxial cable bridge kit
Cable Runs, quantity	4
Mounting	Non-penetrating
Hole Size	19.1 mm 3/4 in
Hole, quantity	4
Includes	Channel Hardware Sleepers, three
Material Type	Galvanized steel
Package Quantity	1

MT-F1542-11



Outline Drawing

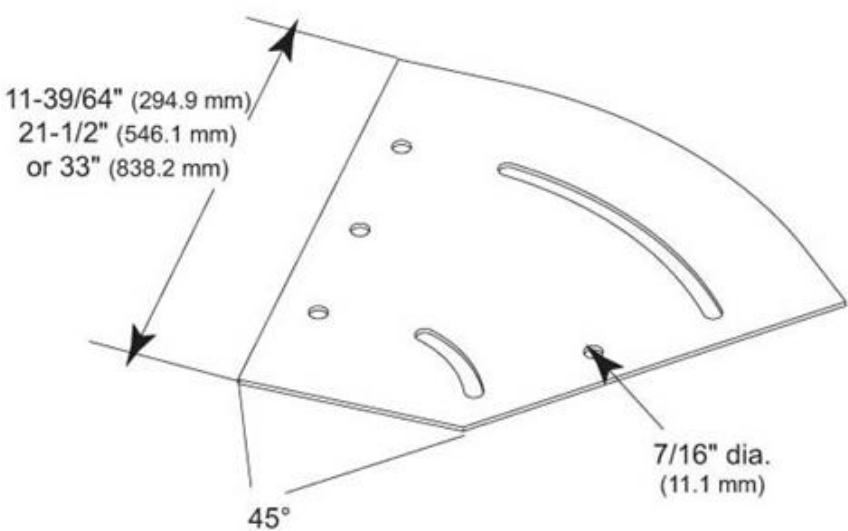

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2008	Designed, manufactured and/or distributed under this quality management system

Included Products

MT-F1598 — PVC Roof Sleeper, for four coaxial cable runs

* Footnotes

Wind Rating	BWS—Base Wind Speed; FBC—Florida Building Code
-------------	--