

## DS-2CE16C2T-IR


### HD720P Turbo HD Bullet Camera



#### Key features

- HD720P Video Output
- Adopt HDTVl Technology
- True Day/Night
- DNR, Smart IR
- 20m IR distance
- IP66 weatherproof

#### Dimensions

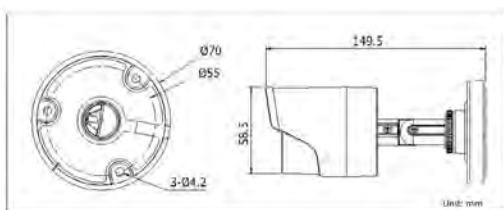

#### Accessories



Video balun  
DS-1H18

#### Available models

DS-2CE16C2T-IR

| DS-2CE16C2T-IR                   |                                                                                        |
|----------------------------------|----------------------------------------------------------------------------------------|
| Camera                           |                                                                                        |
| Image Sensor                     | 1/3" Progressive Scan CMOS                                                             |
| Effective Pixels                 | 1280(H)*720(V)                                                                         |
| Min. Illumination                | 0.01 Lux @(F1.2,AGC ON), 0 Lux with IR                                                 |
| Shutter Time                     | 1/25(1/30) s to 1/50,000 s                                                             |
| Lens                             | 3.6mm (2.8mm, 6mm optional)<br>Angle of View: 76.88°(3.6mm), 99.73°(2.8mm), 50.1°(6mm) |
| Lens Mount                       | M12                                                                                    |
| Angle Adjustment                 | Pan: 0 - 360°, Tilt: 0 - 90°, Rotation: 0 - 360°                                       |
| Day & Night                      | ICR                                                                                    |
| Synchronization                  | Internal synchronization                                                               |
| Video Frame Rate                 | 25 fps (PAL) / 30 fps (NTSC)                                                           |
| HD Video Output                  | 1 Analog HD output                                                                     |
| S/N Ratio                        | More than 52dB                                                                         |
| General                          |                                                                                        |
| Working Temperature/<br>Humidity | -40 °C - 60 °C (-40 °F - 140 °F)<br>Humidity 90% or less (non-condensing)              |
| Power Supply                     | 12 VDC                                                                                 |
| Power Consumption                | Max. 4W                                                                                |
| Weather Proof Ratings            | IP66                                                                                   |
| IR Range                         | Up to 20m                                                                              |
| Dimensions                       | φ70×149.5 mm (φ2.76" ×5.89")                                                           |
| Weight                           | 360 g (0.79 lb)                                                                        |