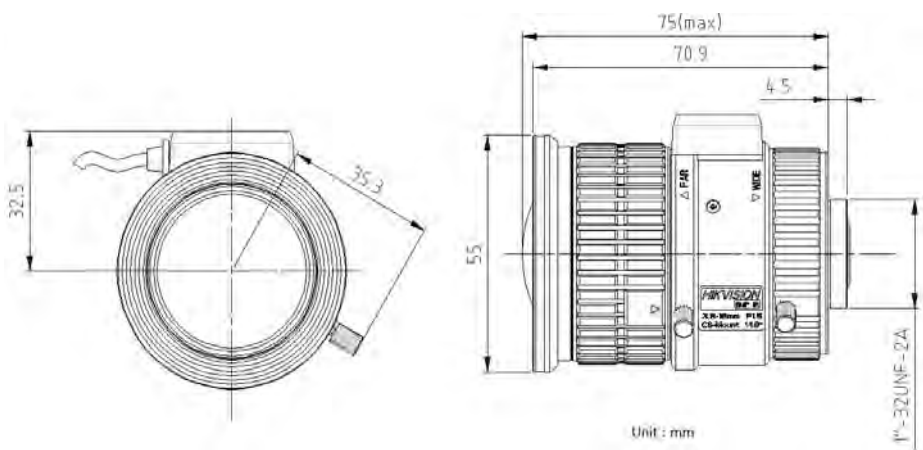


HIKVISION		CCTV LENS SPEC			
Model NO.		HV3816D-8MPIR		Specification	Vari-focal DC Auto Iris 8MP IR ASPHERICAL
Focal Length		3.8-16mm		Mount	CS-Mount
F number		F1.5-C		Flange Back Length	12.5mm
Max. Image format		Φ9mm (1/1.8")		M. O. D	0.1m
Control	Iris	DC Auto Iris		Dimension	Φ55*75
	Focus	Manual		Weight	237g
	Zoom	Manual		Operating Temperature	-10~50℃
Field of View	D	1/1.8"	123.9° ~33.5°	1/2"	115.6° ~31.3°
	H		103.1° ~28.0°		100.7° ~27.3°
	V		68.5° ~18.7°		61.3° ~15.4°
Dimension		 Unit : mm			
Lens Picture					