



# FS-IP14K

## FS-IP14K

---

The FS-IP14K Pro Series was designed to utilize 14.0 megapixel resolution (4352 x 3264) from its 360° field-of-view. Traditional cameras have an inherent weakness: only recording images specifically where they are pointed, zoomed and focused at a given time. The FS-IP14K Pro Series can handle multiple dewarped or corrected perspective angles from its omni-directional vantage point. The Pro Series is perfectly suited for large environments with heavy traffic areas and can drastically reduce the camera count, labor costs, maintenance and investigation time.

## Dimensions

---

- 1.38 x 2.52 x 3.27 in (35.1 x 64 x 83.1 mm)\*
- 0.33 lb (150 g)\*

## Performance Specification

---

- Field of View: 360°
- Sensor: 14.0MP CMOS
- Maximum Resolution: 4352x 3264
- Active Pixel Count: 14,204,928
- Maximum Frame Rate: 6 fps (at max res)
- Compression: MJPEG / H.264
- Streaming: Quad H.264 + MJPEG
- 0.02 Lux (color) at F/1.4
- Backlight Compensation
- Dynamic Range: 65 dB
- Owl Eye™ Noise Reduction
- Full Onvif Compatibility

\*Without lens

## Technical Specification

---

- Lens: CS Mount
- Motion Detection
- UDP, TCP, HTTP, TFTP, RTSP
- 100/10 LAN Connection

## Electrical Specification

---

- DC Voltage: 12VDC
- PoE: 4 Watts maximum

## Environmental Specification

---

- Operating Temperature: -4° - 122° F  
-20° - 50° C
- Humidity: 0% to 90%, No condensation

## Warranty

---

- 3 Year, Parts and Labor

## Images




1



2

## Dimensional Outline

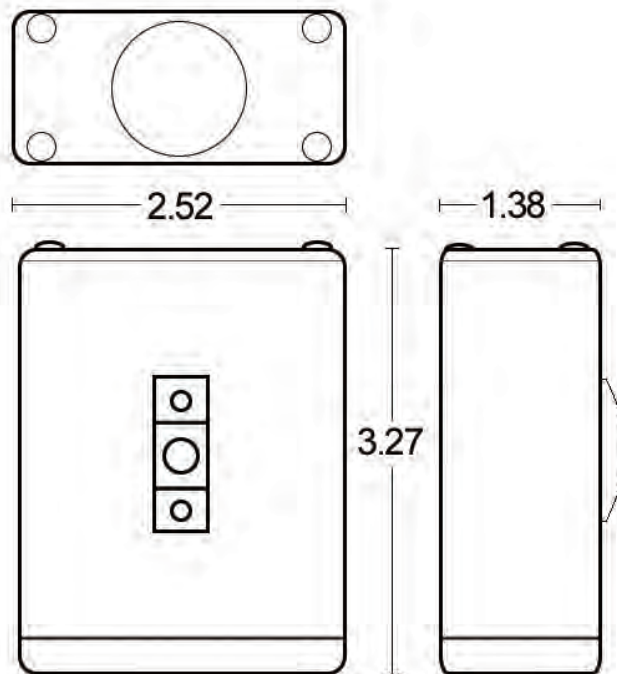

## Compatible Accessories

- FS-DM-DOME
- FS-DM-WALL
- FS-DM-CEILING
- FS-DM-CORNER
- FS-DM-POLE
- FS-DM-RECESSED