



sentry360

IS-IP14K
Camera Specifications



IS-IP14K

IS-IP14K

The IS-IP14K is a professional-grade multi-megapixel network security and surveillance camera. With an active resolution more than 32x that of traditional CCTV cameras, the IS-IP14K is a state-of-the-art surveillance system.

The IS-IP14K is a great choice in applications requiring the highest forensic detail.

Dimensions

- 1.38 x 2.52 x 2.31 in (35.1 x 64 x 58.7 mm)*
- 0.33 lb (150 g)*

Performance Specification

- Sensor: 14.0MP CMOS
- Maximum Resolution: 4384 x 3288
- Active Pixel Count: 14,414,592
- Maximum Frame Rate: 6 fps (at max res)
- Compression: MJPEG / H.264
- Streaming: Quad H.264 + MJPEG
- 0.01 Lux (color) at F/1.4
- Backlight Compensation
- Dynamic Range: 65 dB
- Owl Eye™ Noise Reduction
- Full Onvif Compatibility

*Without lens

Technical Specification

- Lens: CS Mount
- Motion Detection
- UDP, TCP, HTTP, TFTP, RTSP
- 100/10 LAN Connection

Electrical Specification

- PoE / 10 - 16V
- 4 - 4.5 watts

Environmental Specification

- Operating Temperature: -4° - 122° F
-20° - 50° C
- Humidity: 0% to 90%, No condensation


Warranty

- 3 Year, Parts and Labor

Images



Dimensional Outline

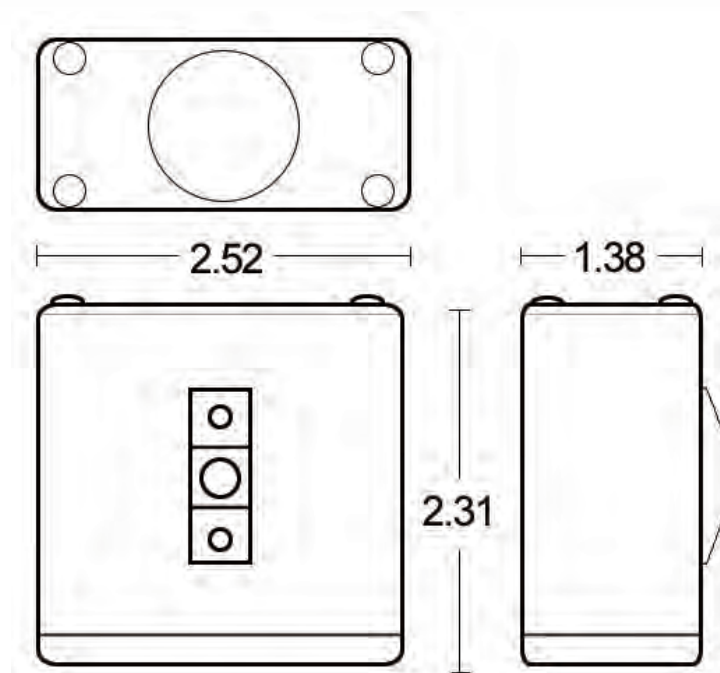

Compatible Accessories

- IS-IR-850-50
- IS-IR-850-70
- IS-IR-850-100
- IS-OH-HB
- IS-IH-WALL
- IS-IH-JPIPE
- 14 MP Lenses