



IS-IP4K

IS-IP4K

The IS-IP4K is a professional-grade 4K resolution network security and surveillance camera. Engineered to meet the highest standard in ultra-resolution surveillance, the IS-IP4K is capable of producing video that is 32x the quality of traditional CCTV cameras. Its small form factor and low power requirement make the IS-IP4K a clear choice for any security application requiring precision detail on a consumer budget.

Dimensions

- 1.38 x 2.52 x 3.27 in (35.1 x 64 x 83.1 mm)*
- 0.33 lb (150 g)*

Performance Specification

- Sensor: 12.6MP CMOS
- Maximum Resolution: 4096 x 3072
- Active Pixel Count: 12,582,912
- Maximum Frame Rate: 10 fps (at max res)
- Compression: MJPEG / H.264
- Streaming: Quad H.264 + MJPEG
- 0.02 Lux (color) at F/1.4
- Backlight Compensation
- Dynamic Range: 65 dB
- Owl Eye™ Noise Reduction
- Full Onvif Compatibility

*Without lens

Technical Specification

- Lens: CS Mount
- Motion Detection
- UDP, TCP, HTTP, TFTP, RTSP
- 100/10 LAN Connection

Electrical Specification

- PoE / 10 - 16V
- 4.5 watts

Environmental Specification

- Operating Temperature: -4° - 122° F
-20° - 50° C
- Humidity: 0% to 90%, No condensation


Warranty

- 3 Year, Parts and Labor

Images



Dimensional Outline

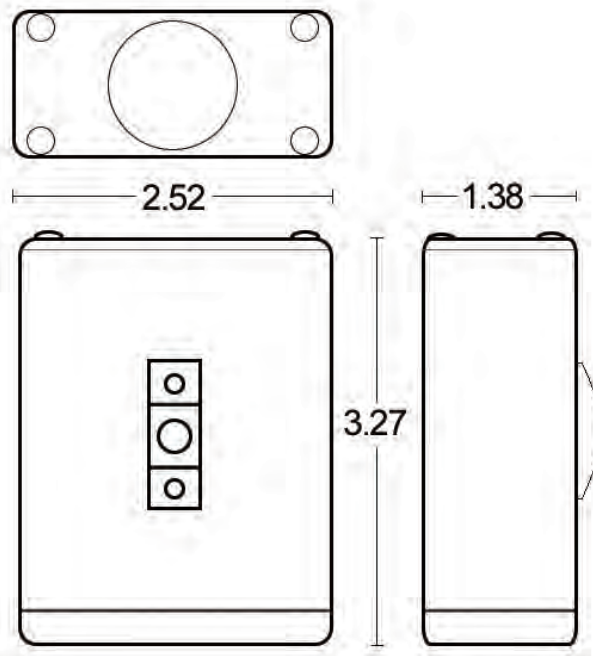

Compatible Accessories

- IS-IR-850-50
- IS-IR-850-70
- IS-IR-850-100
- IS-OH-HB
- IS-IH-WALL
- IS-IH-JPIPE
- 14 MP Lenses