




Detailed Specifications & Technical Data for P/N : 13.005.03

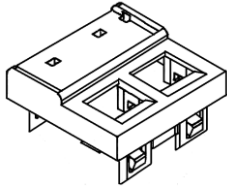

General Description:

Dual coupler with shutters and label slot for AVAYA modules.

Usage

Suitable Applications: Compatible with a variety of RJ 45 AVAYA modules

Related Parts: Compatible with LEGRAND MOSAIC 45 X45 series faceplates.

Suitability - Indoor: Yes

Physical Characteristics

Max. Capacity: 2-port

Front Connection: Flush

Dimensions:

Height (cm.) Width (cm.) Depth (cm.)

4,45 X 4,45 X 2,32

Weight: 0,012 kg.

Materials

Description Material

Polycarbonate- ULV2

Color: Elec. White

Packaging

Packaging: Individually packaged in a plastic bag.

Included Parts: Carton label, clear window

Mechanical Characteristics

Connector/Hardware Retention: 7 kg.

Storage Temperature Range: -10°C to +70°C

Installation Temperature Range: -10°C to +60°C

Operating Temperature Range: -10°C to +60°C

Applicable Standards & Environmental Programs

EU Directive 2002/95/EC (RoHS): Yes