

MINI STAINLESS STEEL WALL TELEPHONES

321/ 323 MINI STAINLESS STEEL WALL TELEPHONES

CEECO's SSW Series telephones are our longest standing and most popular model, proving their durability over the test of time. Their small size makes them an easy and convenient fit for most locations, while providing the reliable communication you can depend on. Stainless steel construction, enhanced fraud protection features, and industrial grade components make this phone ideal for your toughest environments. The SSW Series telephone is a great solution for courtesy, critical and security communication in many industries, including prisons, mental hospitals, college, and universities, airports, warehouses and more. CEECO's dedicated sales force, knowledgeable technical support, and readily available telephones and parts gives you the product and service you can count on. Manufactured in the USA, CEECO telephones are Built to Last and are supported by over 84 years of experience.



Made in the USA

FEATURES

Measurements:

5"W x 10 3/4"H x 5 1/2"D (with handset on hook)

Stainless Steel Construction with Tamper Resistant Hardware

Marine Quality Chrome Hookswitch

Vandal Resistant Chrome Tone Dial


Hearing Aide Compatible Armored Cord Handset with Steel Lanyard

Mounting Backplate Included

Line Powered

Requires 301-037 Security Tool for Installation

1 Year Warranty and Lifetime Support

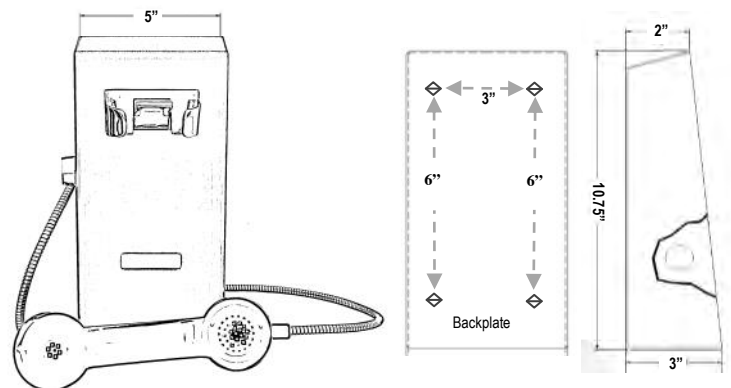





CEECO has been providing telecom solutions since 1930. Our vandal resistant technology focuses on providing public communication solutions while reducing replacement and repair costs, lowering the customer's total cost of ownership. CEECO also offers custom design and branding to your specifications. Our commitment to providing expert service and support extends beyond the warranty of our product. We offer support for the life of the product! CEECO is devoted to giving you the quality and service you deserve.

STAINLESS STEEL MINI WALL TELEPHONES

321 STAINLESS STEEL MINI WALL TELEPHONES

Sturdy and attractive stainless steel mini wall telephones

KEYPAD TELEPHONES	AUTODIAL TELEPHONES	OTHER TELEPHONES	RING INDICATOR TELEPHONES
 <p>SSW-321-F</p>	 <p>SSW-321-D</p>	 <p>SSW-321-X SSW-323-E</p>	 <p>SSW-321-F-M-IVC-RIS SSW-321-F-RIL</p>
Dimensions: 5" W x 10 3/4" H x 5 1/2" D	Dimensions: 5" W x 10 3/4" H x 5 1/2" D	Dimensions: 5" W x 10 3/4" H x 5 1/2" D	Dimensions: 5" W x 10 3/4" H x 5 1/2" D
Mini Stainless Steel, Wall Telephone Chrome Hookswitch and Cradle 32" Armored Cord Handset <ul style="list-style-type: none"> Steel lanyard and swivel Optional cord lengths Mounting Backplate SSW-323-F Model Chrome Tone Dial Keypad (F) <ul style="list-style-type: none"> Ability to allow incoming or outgoing calls SSW-323-F Model Chrome Tone Dial Keypad (F) SMART Features <ul style="list-style-type: none"> Ability to allow or block incoming calls Call restriction capability Option to auto dial PBX or access numbers Programmable conversation time-out Optional speed dialing 	Mini Stainless Steel, Wall Telephone Chrome Hookswitch and Cradle 32" Armored Cord Handset <ul style="list-style-type: none"> Steel lanyard and swivel Optional cord lengths SSW-321-D Model Automatic Dialer (D) <ul style="list-style-type: none"> Activated when the handset is lifted Will auto dial a single number from 1-11 digits SSW-321-D2 Model Automatic Dialer (D2) <ul style="list-style-type: none"> Will dial a second number if called party doesn't answer SSW-323-D Model Automatic Dialer (D) SMART Features <ul style="list-style-type: none"> Can be programmed to dial up to 25 digits Optional access code prefix dialing No incoming calls allowed 	Mini Stainless Steel, Wall Telephone Chrome Hookswitch and Cradle 32" Armored Cord Handset <ul style="list-style-type: none"> Steel lanyard and swivel Optional cord lengths Mounting Backplate SSW-321-X Model Ring-down operation (X) <ul style="list-style-type: none"> Activated when the handset is lifted Will allow incoming calls Initiate a call when programmed through a PBX or phone system SSW-323-E Model Twelve Button Keypad (E) <ul style="list-style-type: none"> Each button is programmable to speed dial a single number from 1-23 digits Label area provided to list call destination next to each button Ability to allow or block incoming calls Speed dial capability only, no other calls allowed 	Mini Stainless Steel, Wall Telephone Chrome Hookswitch and Cradle 32" Armored Cord Handset <ul style="list-style-type: none"> Steel lanyard and swivel Optional cord lengths Mounting Backplate SSW-321-F-RIS Model Chrome Tone Dial Keypad (F) Ring Indication Strobe (RIS) <ul style="list-style-type: none"> Flashing blue light SSW-321-F-RIL Model Chrome Tone Dial Keypad (F) Ring Indicator Light (RIL) <ul style="list-style-type: none"> Blue light ring indicator located on the phone panel for visibility

ADDITIONAL OPTIONS

IP- Voice over Internet Protocol Version Available on All Model (SIP)

-M	-IVC	-ACH**	-ACH*	-CCH*	-RIS	-RIL	-BR
							
Magnetic Hookswitch <ul style="list-style-type: none"> Completely Sealed No Moving Parts 	<ul style="list-style-type: none"> Push Button Volume Control Background Noise reduction 	Other Length armored cord from 12" to 72"(inches). Example: -ACH12 12" Long	ACHW- White Handset ACHR- Red Handset (Black is standard)	Coiled cord available from 5', 10', & 15' (feet). Example: -CCH5 5' Long	Ring Indicator Flashing Blue Light (Requires AC Power)	Ring Indicator Light located on the phone panel for visual ring indication.	Braille Emergency Plate (EMERG. PHONE)

Visit our website at www.ceeco.net or call us at 863-357-0798 for detail specifications on any of our models.