

SSP-313-FD SPECIFICATIONS


STAINLESS STEEL PANEL TELEPHONE WITH SMART FEATURES, KEYPAD & AUTODIAL BUTTON

Durable stainless steel flush mount panel telephone with keypad and autodial push button. Programmable prefix or access dialing capability, allow or block incoming calls, 40 (1-11 digits) programmable speed dialing locations. Autodial button dials a preprogrammed number from 1-11 digits. Equipped with marine quality chrome tone dial keypad and mechanical hookswitch, ID window or optional (-IVC) pushbutton volume control with background noise reduction, and 32" hearing aid compatible armored cord handset. Telephone can be flush mounted or installed in our 331-005 weatherproof or 331-HOB weather resistant housing.



SPECIFICATIONS

Panel Size:	7 1/6"W x 11 1/4"H 2"D (Behind Panel) 3"D (Front Panel & Handset on Hook)
Weight:	Approximately 6 lbs.
Mounting Instructions:	Flush Mounted Weatherproof Housing (WPP) Weather Resistant Open Enclosure (HOB)
Environment:	Temperature: -30°C (-22°F) to 60°C (140°F) Humidity: 0%-90% non-condensating
Programming:	VIA DTMF keypad
Memory Retention	Lithium Battery - Long Life
Input Power:	Telephone Line Powered
Loop Current:	25mA min. 80mA max.
Impedance:	600 ohms
Type Jack:	RJ11C
Ringer Equivalency:	0.4A
Hearing Aid Compatible:	Meets EIA standards
UL & FCC Registration:	Certified
ACCESSORIES:	301-064 Security Tool (only required for installation when in HOB or WPP)

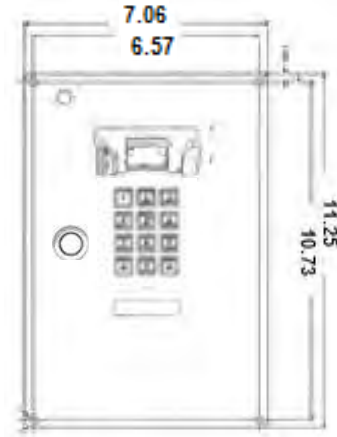

ADDITIONAL OPTIONS								
IP - Voice over Internet Protocol Version available on all models (SIP)								
-M	-IVC	-ACH**	-ACH*	-CCH*	-LB	Open Enclosure Housing	Weatherproof Housing	-RIL
Sealed Magnetic Hookswitch • Completely Sealed • No Moving Parts	Internal Volume Control • Push Button Volume Control • Background Noise reduction	Varies armored cord from length 14" to 72" Example: ACH14: 14" armored cord	Varies handset color -ACHW White handset -ACHR Red handset	Coiled cord available from 5', 10', & 15' (feet). Example: -CCH5 5' Long	Handset w/ internal steel lanyard (braided metal rope) and lanyard mounting bracket that is secured onto panel for added strength.	-331-HOB Standard Black Housing -331-HOB-R Red Housing -331-HOB-S Stainless Steel Housing	-331-005 Standard Black & TELEPHONE on Door -331-005-EMER Black & EMERGENCY on Door -331-005-R Red & EMERGENCY on Door -331-005-R-TEL Red & TELEPHONE on Door -331-005-Y Yellow & EMERGENCY on Door -331-005-Y-TEL Yellow & Telephone on Door 331-005-G Grey & TELEPHONE on Door 331-005-G-EMER Grey & EMERGENCY on Door	Ring Indicator Light located on the phone panel for visual ring indication