

# SSP-363-E SPECIFICATIONS


## LARGE FLUSH OR WALL MOUNTED HANDSET PANEL TELEPHONE WITH 12 BUTTON AUTODIAL KEYPAD








Sturdy heavy gauge stainless steel flush mount panel telephone with twelve (12) automatic dialer push buttons. Each push button is programmable to dial 1-23 digits, PBX, prefix, or access dialing capability, and incoming calls may be allowed or blocked. Phone is built with marine quality chrome tone dial keypad with 2 column, 12 button configuration and mechanical hook switch, label area next to each push button to list destination button will call, 32" armored cord handset, instruction or advertising window, tamper resistant security screws, and rough in steel mounting box. Optional (-SW) stainless steel surface mount box available.

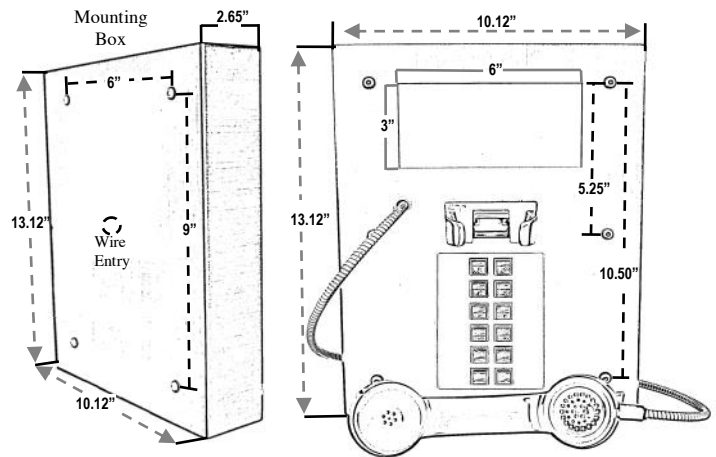

### SPECIFICATIONS

<b>Panel Size:</b>	10.12"W x 13.12"H 2"D (Behind Panel) 3"D (Front Panel & Handset on Hook) 5.65"D (With Wall Mounting Box and Handset on Hook)
<b>Weight:</b>	Approximately 10 lbs.
<b>Mounting Instructions:</b>	Rough-in flush mounting box <b>(Standard)</b> Dimensions: 8.50" W x 11.50"H x 2.75" D 3 mounting holes per side of panel spaced 5.25" apart vertically and two holes spaced 7.8" apart horizontally Surface Wall Mounting Box <b>(-SW)</b> 4 holes spaced 6W" x 9H"
<b>Environment:</b>	Temperature: -30°C (-22°F) to 60°C (140°F) Humidity: 0%-90% non-condensing
<b>Programming:</b>	Via DTMF Keypad
<b>Input Power:</b>	Telephone Line Powered
<b>Loop Current:</b>	25mA min to 80mA max
<b>Impedance:</b>	600 ohms
<b>Type Jack:</b>	RJ11C
<b>Ringer Equivalency:</b>	0.4A
<b>Hearing Aid Compatible:</b>	Meets EIA standards
<b>UL &amp; FCC Registration:</b>	Certified
<b>ACCESSORIES:</b>	301-037 Security Tool (required for installation When in a Box)



ADDITIONAL OPTIONS						
IP - Voice over Internet Protocol Version available on all models (SIP)						
-M	-ACH**	-CCH*	-LB	-RIL	-SW	Standard rough in mounting box
						
Sealed Magnetic Hookswitch • Completely Sealed • No Moving Parts	Optional armored cord lengths from 5', 14" to 72". Example: ACH18 (18" armored cord handset)	Coiled cord available from 5', 10', & 15' (feet). Example: -CCH5 5' Long	Handset w/ internal steel lanyard (braided metal rope) and lanyard mounting bracket that is secured onto panel for added strength.	Ring Indicator Light located on the phone panel for visual ring indication.	Stainless steel surface mounting box Dimensions: 10.12" W x 13.12"H x 2.65"D 4 holes spaced 6W" x 9H"	Rough-in flush mounting box Dimensions: 8.50" W x 11.50"H x 2.75" D



Providing Telecommunication Solutions Since 1930

Communication Equipment  
& Engineering Company

<http://www.ceeco.net>  
Email: [sales@ceeco.net](mailto:sales@ceeco.net)

519 SW Park Street  
Okeechobee, FL  
Voice 863-357-0798  
Fax 863-357-0006