

# SSW-321-D SPECIFICATIONS

## MINI WALL HANDSET TELEPHONE WITH AUTODIAL


*Standard Analog Power, but also available in VoIP versions*

Strong and compact small stainless steel surface mount wall telephone that will autodial a preprogrammed number when the handset is lifted off-hook. The direct dial or hotline phone can be preprogrammed to dial 1-11 digits. Phone is constructed with a marine quality chrome mechanical or magnetic hookswitch, ID window or optional volume control button with background noise reduction, 32" hearing aid compatible armored cord handset with internal steel lanyard and swivel, which is anchored into the housing, tamper resistant security screws, and steel mounting backplate for easy installation. For the toughest environments shorter handset lengths are available in 10, 12, and 18 inch lengths.



### SPECIFICATIONS

<b>Panel Size:</b>	5" W x 10.75" H x 3" D 5.5" D With handset on Hook
<b>Weight:</b>	Approximately 7 lbs.
<b>Mounting Instructions:</b>	<b>Vertical Surface Mount:</b> Separate the cover assembly from the backplate. The plate assembly is designed to be mounted on any flat vertical surface. <ul style="list-style-type: none"> <li>Four mounting holes: 3" W x 6" H</li> </ul>
<b>Environment:</b>	Temperature: -30°C (-22°F) to 60°C (140°F) Humidity: 0%-90% non-condensing
<b>Input Power:</b>	Telephone Line Powered
<b>Programing:</b>	Via mini-Jumpers on ATD 11 Board
<b>Loop Current:</b>	23mA min to 80mA max
<b>Impedance:</b>	600 ohms
<b>Type Jack:</b>	RJ11C
<b>Ringer Equivalency:</b>	0.4A
<b>Hearing Aid Compatible:</b>	Meets EIA standards
<b>UL&amp; FCC Registration:</b>	Certified
<b>ACCESSORIES:</b>	301-037 Security Tool (required for installation)

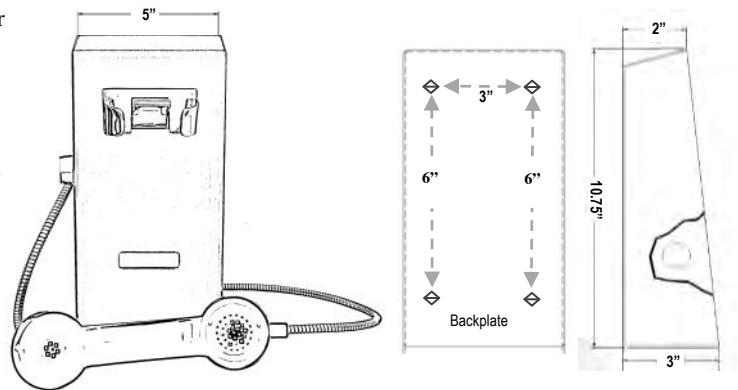

### ADDITIONAL OPTIONS

IP - Voice over Internet Protocol Version available on all models (SIP)

-M	-IVC	-ACH**	-ACH*	-CCH*	-RIL	-RIS
<b>Sealed Magnetic Hookswitch</b> <ul style="list-style-type: none"> <li>Completely Sealed</li> <li>No Moving Parts</li> </ul>	<b>Push Button Volume Control</b> <ul style="list-style-type: none"> <li>Background Noise reducer</li> </ul>	Other Length armored cord from 12" to 72"(inches). Example: <b>-ACH12</b> 12" Long	<b>ACHW</b> -White Handset <b>ACHR</b> -Red Handset (Black is standard)	Coiled cord available from 5', 10', & 15' (feet). Example: <b>-CCH5</b> 5' Long	Ring Indicator Light located on the phone panel for visual ring indication	Ring Indicator Flashing Blue Light (Requires AC Power)



*Providing Telecommunication Solutions Since 1930*

Communication Equipment  
& Engineering Company

<http://www.ceeco.net>  
Email: [sales@ceeco.net](mailto:sales@ceeco.net)

519 SW Park Street

Okeechobee, FL

Voice 863-357-0798

Fax 863-357-0006