

# WPP-531-D SPECIFICATIONS

## HANDSFREE SPEAKERPHONE WITH PUSH-BUTTON AUTODIAL IN A WEATHERPROOF HOUSING


*Standard Analog Power, but also available in VoIP versions*

Heavy duty stainless steel handsfree speakerphone in a cast aluminum black waterproof housing with TELEPHONE on door and pin latch for wall or pole mount. Designed to automatically dial a preprogrammed number from 1-11 digits when the button is pushed and red/green LED light provides visual indication of call progress. Capable of dialing a PBX or access number, block or allow incoming calls, and provides call duration time-out from 1-9 minutes or no time-out. Telephone can not be left off-hook, as it detects when called party hangs up and resets itself. Equipped with a weatherproof, puncture resistant speaker and microphone and tamper resistant security screws. ADA Emergency features Available. WPP models available in black, (-R) red, (-Y) Yellow, or (-G) Gray with TELEPHONE or EMERGENCY on door.







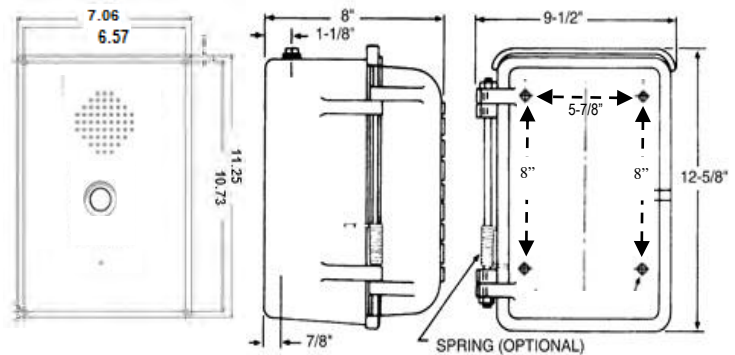

### SPECIFICATIONS

<b>Panel Size:</b>	7 1/6"W x 11 1/4"H
<b>Weatherproof Housing:</b>	9 1/2"W x 12 5/8"H x 8"D (Including Door)
<b>Weight:</b>	Approximately 17 lbs.
<b>Mounting Instructions:</b>	Weatherproof Housing 4 holes spaced 8" x 5 7/8" Also available pole mounting bracket
<b>Environment:</b>	Temperature: -30°C (-22°F) to 60°C (140°F) Humidity: 0%-90% non-condensing
<b>Programming:</b>	Via DTMF Keypad
<b>Input Power:</b>	Telephone Line Powered
<b>Loop Current:</b>	30mA min to 80mA max
<b>Impedance:</b>	600 ohms
<b>Type Jack:</b>	RJ11C
<b>Ringer Equivalency:</b>	0.4A
<b>UL &amp; FCC Registration:</b>	Certified
<b>ACCESSORIES:</b>	301-064 Security Tool (required for installation)



### ADDITIONAL OPTIONS

**IP - Voice over Internet Protocol Version available on all models (SIP)**

-ADA	Weatherproof Housing	-ST/-SB/-RST	-RIL	-SP	Pole Mount	Additional Options & Features
						Auto Answer (AA) Remote Programming (RP) Voice Announcement (VA)
<ul style="list-style-type: none"> <li>Red/ green LED call progress indicator light</li> <li>Braille Emergency Plate "EMERG. PHONE"</li> <li>Red push button</li> </ul>	Standard Black & TELEPHONE on Door -B-EMER Black & EMERGENCY on Door -R Red & EMERGENCY on Door -R-TEL Red & TELEPHONE on Door -Y Yellow & EMERGENCY on Door -Y-TEL Yellow & Telephone on Door -G Grey & TELEPHONE on Door -G-EMER Grey & EMERGENCY on Door	Blue Strobe Light option: <ul style="list-style-type: none"> <li>Steady on</li> <li>Flashing</li> <li>For location visibility</li> <li>Requires AC power</li> </ul>	Ring Indicator Light located on the phone panel for visual ring indication.	Spring loaded door option	Pole Mounting bracket fits poles 2.5" - 6".	



*Providing Telecommunication Solutions Since 1930*

Communication Equipment  
& Engineering Company

<http://www.ceeco.net>  
Email: [sales@ceeco.net](mailto:sales@ceeco.net)

519 SW Park Street

Okeechobee, FL

Voice 863-357-0798

Fax 863-357-0006