

M12-Round-Plug Connector, Single-Ended Cordsets, According to IEC 61076-2-101

RKT | RKWT




3-, 4-, 5-, and 8-Poles

Actuator/sensor cordset, single-ended, M12, 3-, 4-, 5-, and 8-poles, female straight connector with self-locking thread and molded cable.

— RST 8-627 has black cable and overmold —


RKT

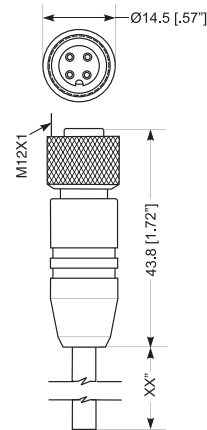

Actuator/sensor cordset, single-ended, M12, 3-, 4-, 5-, and 8-poles, female 90° connector with self-locking thread and molded cable.

— RKWT 8-627 has black cable and overmold —

RKWT

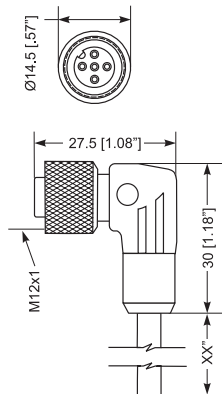

Pin Assignments

M12 - Female

3 poles



1 = brown
2 = n.c.
3 = blue
4 = black

4 poles



1 = brown
2 = white
3 = blue
4 = black

5 poles



1 = brown
2 = white
3 = blue
4 = black
5 = grey

8 poles



1 = white
2 = brown
3 = green
4 = yellow
5 = grey
6 = pink
7 = blue
8 = red



M12-Round-Plug Connector, Single-Ended Cordsets, According to IEC 61076-2-101

RKT | RKWT

Technical Data

Environmental

Degree of protection
Operating temperature range

IP 67 / NEMA 6P
PUR: -40°C (-40°F) / +80°C (176°F)
PVC: -40°C (-40°F) / +90°C (194°F)
TPE: -40°C (-40°F) / +90°C (194°F)

Mechanical

Housing / Molded body

PUR, yellow
RKT/RKWT 8-627: PUR, black
PUR, Yellow
RKT/RKWT 8-627/727: PUR, orange

Insert

Contacts
Coupling nut
O-ring

CuSn, gold over nickel-plated
CuZn, nickel-plated
FKM or Viton

Electrical

Current rating
RKT/RKWT 8-XXX:

4 A
1.5A

Voltage rating
RKT/RKWT 8-XXX:

250 V
30 V AC /36 V DC

Cable Specifications

Cable No.	Outer Jacket	Gauge	Jacket Color	OD
602	PUR	18AWG	Yellow	.230" (5.8 mm)
Continuous flex rating and suitable for general C-track usage. 1 million cycles at minimum bend radius 10X cable diameter.				
610	PUR	22AWG	Yellow	.190" (4.8 mm)
612	PVC	22AWG	Yellow	.210" (5.3 mm)
627	PVC	24AWG	Black	.232" (5.9 mm)
632	PVC	22AWG	Yellow	.190" (4.8 mm)
633	PVC	22AWG	Yellow	.190" (4.8 mm)
637	TPE/PLTC	18AWG	Yellow	.280" (7.1 mm)
643	TPE/PLTC	22AWG	Yellow	.246" (6.2 mm)
644	PUR	22AWG	Yellow	.210" (5.3 mm)
645	PUR	18AWG	Yellow	.220" (5.6 mm)
679	PUR	22AWG	Yellow	.190" (4.8 mm)
713	TPE/PLTC	22AWG	Yellow	.280" (7.1 mm)
727	TPE/PLTC	22AWG	Yellow	.335" (8.5 mm)
731	TPE/PLTC	18AWG	Yellow	.261" (6.6 mm)
794	TPE/PLTC	18AWG	Yellow	.304" (7.7 mm)

Part Number	Pins	Outer Jacket	Standard Cable Lengths	Characteristics
RKT 4-3-731/...M RKWT 4-3-731/...M	3	TPE/PLTC	2 M / 5 M / 10 M	
RKT 4-3-632/...M RKWT 4-3-632/...M		PVC	2 M / 5 M / 10 M	
RKT 4-3-645/...M RKWT 4-3-645/...M		PUR	2 M / 5 M / 10 M	
RKT 4-3-610/...M RKWT 4-3-610/...M		PUR	2 M / 5 M / 10 M	
RKT 4-637/...M RKWT 4-637/...M	4	TPE/PLTC	2 M / 5 M / 10 M	
RKT 4-633/...M RKWT 4-633/...M		PVC	2 M / 5 M / 10 M	
RKT 4-643/...M RKWT 4-643/...M		TPE/PLTC	2 M / 5 M / 10 M	
RKT 4-602/...M RKWT 4-602/...M		PUR	1 M / 2 M / 5 M / 10 M	
RKT 4-679/...M RKWT 4-679/...M		PUR	2 M / 5 M / 10 M	
RKT 5-612/...M RKWT 5-612/...M	5	PVC	2 M / 5 M / 10 M	
RKT 5-644/...M RKWT 5-644/...M		PUR	2 M / 5 M / 10 M	
RKT 5-713/...M RKWT 5-713/...M		TPE/PLTC	2 M / 5 M / 10 M	
RKT 5-794/...M RKWT 5-794/...M		TPE/PLTC	2 M / 5 M / 10 M	
RKT 8-627/...M RKWT 8-627/...M	8	PVC	2 M / 5 M / 10 M	
RKT 8-727/...M RKWT 8-727/...M		TPE/PLTC	2 M / 5 M / 10 M	