


Mini Double-Ended Cordsets

RSRK 40-839 | RSRK 50-877

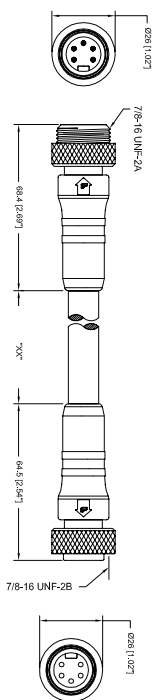

Description

MINI, Double-Ended Cordset, Straight, Male (external threads) to Female (internal threads), 4- and 5-Pole, 16 AWG, Yellow TPE (TC-ER) Cable, U.S. Color Code, IP 68 and NEMA 6P Rated.

Technical Data

Material	
Molded body	PUR, yellow
Coupling nut	Aluminum, e-coated or anodized black
Contacts	Brass, gold over nickel plated
Insert	PUR, yellow

Electrical	
Current rating	8 A
Voltage rating	600 V

Mechanical	
Temperature	-30°C to + 90°C
Protection	IP 68, NEMA 6P

Cable	
Jacket	Yellow, TPE
Gauge	16 AWG stranded copper
UL Approval	TC-ER
Outside diameter	839: .342"
	877: .371"

Part Number

RSRK 40-839/1M
RSRK 40-839/2M
RSRK 40-839/3M
RSRK 40-839/5M
RSRK 40-839/10M
RSRK 40-839/20M
RSRK 50-877/1M
RSRK 50-877/2M
RSRK 50-877/3M
RSRK 50-877/5M
RSRK 50-877/10M
RSRK 50-877/20M

Pin Assignments

Face View 7/8"

