



## Certifier10G™

The cost-effective copper certification handheld

Certifier10G is the cost-effective solution for testing and certifying copper up to Category 6A. An entry-level handheld, the Certifier10G has the same capabilities as the industry-standard Certifier40G without the added complexity of fiber or Class FA support.

### Drive User Efficiency

The Certifier10G is not only the most advanced solution available, it is also the fastest and most complete. When certifying copper users will get the job done right and on time — the first time!

- Gain complete test visibility at both local and remote ends
- Pre-configured with all leading manufacturer's cabling specifications



### Key Benefits

- Achieve copper network certification with one device
- Optimize productivity with the industry's fastest test workflow
- Obtain comprehensive results for the latest TIA-568 and ISO 11801 requirements
- View test set up and results data and edit labels at both local and remote ends

### Features

- Permanent link and channel adapters for certifying to TIA category 5e/6/6A
- Integrated, standards-based certification labeling and reporting

### Applications


- Complete TIA 568/ISO 11801 copper and fiber certification
- TIA-942-A data center certification

### Comprehensive, Easy-to-Use Reporting

Manage your test results and generate professional reports with J-Reporter software (included), the JDSU reporting platform.

Additional features include:

- Adding a company's logo and name
- Reporting in summary or detail
- Creating hierarchies for record keeping

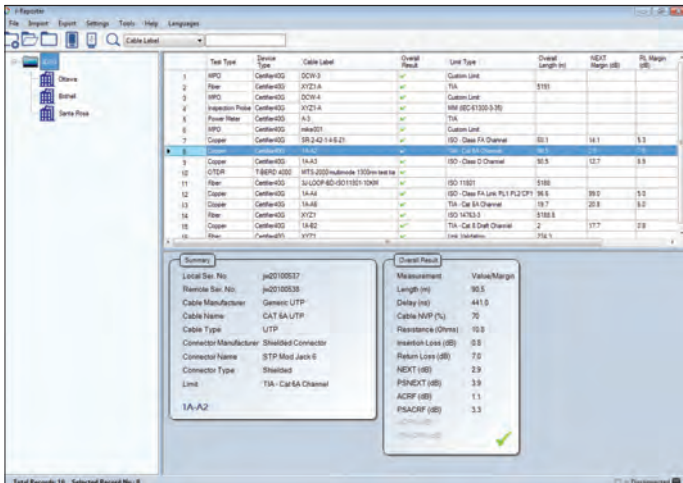

J-Reporter



USB flash drive supports transferring test results



For fiber testing and certification capabilities, combine the Certifier10G with one of the market-leading JDSU fiber testers, such as the T-BERD/MTS-2000

### Certifier40G — The All-in-One Copper and Fiber Solution

The Certifier40G performs complete copper, fiber, MPO, and fiber end-face certification to the latest enterprise connectivity industry standards and requirements with one tester. Visit [www.jdsu.com/go/Certifier40G](http://www.jdsu.com/go/Certifier40G) or contact JDSU for more information.

### Ordering Information

Description	Part Number*
Certifier10G copper	NGC-500-6A

The copper kit includes all adapters and cords for testing links and channels to CAT6A.

\*Append model number with -NA, -UK, -EU, -AU for regional power cords.



Two complete units minimize time initiating, naming, and saving results



Copper kit



**North America**  
**Latin America**  
**Asia Pacific**  
**EMEA**

Toll Free: 1 855 ASK-JDSU  
 Tel: +1 954 688 5660  
 Tel: +1 800 223 7070  
 Tel: +49 7121 86 2222

(1 855 275-5378)  
 Fax: +1 954 345 4668  
 Fax: +65 6602 8301  
 Fax: +49 7121 86 1222