



DATA SHEET

Polycom® CX3000 IP Conference Phone Optimized for use with Microsoft® Lync®

The Polycom® CX3000 IP conference phone delivers exceptional conference call performance in Microsoft® Lync® environments. It features Polycom® HD Voice™ technology for crystal-clear calls and robust interoperability with Lync for an enhanced user experience and easy setup and configuration.

CX3000 IP conference phone features embedded Microsoft Lync software, delivering a familiar user interface for conference call participants. The large high-resolution color display and easy navigation buttons enable familiar dialing controls, calendar and contact directory access, and presence indication. The conference phone also features a USB port for “Better Together” features when connected to a PC running Microsoft Lync software. For IT administrators, seamless integration with Microsoft Lync and built-in Power over Ethernet (PoE) make installation simple and seamless.

Utilizing Polycom HD Voice technology, Polycom CX3000 IP conference phone boosts productivity and reduces listener fatigue by turning ordinary conference calls into clear interactive conversations. The combination of Microsoft RTAudio technology with Polycom acoustic technology captures both the deeper lows and higher frequencies of the human voice for conference calls that sound as natural as being there.

The acoustics and audio performance in Polycom CX3000 IP conference phone demonstrate why Polycom has been the global market leader in conference phones for nearly 20 years. From full-duplex technology that eliminates distracting drop-outs to the latest echo cancellation advancements, only Polycom can deliver a conference phone experience with no compromises. Conference calls are made more productive and efficient by three sensitive microphones with 360° coverage that allow users to speak in a normal voice and be heard clearly from up to 12 feet away. The phone also features technology that resists interference from mobile phones and other wireless devices, delivering clear communications without distractions.

Polycom and Microsoft solutions


Polycom offers the most comprehensive voice and video collaboration solutions for Microsoft Unified Communications environments. Polycom and Microsoft provide a fully unified, intuitive set of collaboration solutions that enables individuals and groups to instantly see, hear, and talk with colleagues around the world. The result is improved collaboration, streamlined operations and faster more informed decisions. Visit www.polycom.com/microsoft to learn more.

HDvoice



Benefits

- **Unparalleled clarity**—Polycom® HD Voice™ technology makes your conference calls sound amazingly clear and life-like
- **More productive conference calls**—Patented Polycom® Acoustic Clarity™ technology delivers the best conference phone experience with no compromises
- **Ensure everyone is heard loud and clear**—Enjoy a 12-foot microphone pick-up range, with optional expansion microphones also available
- **Seamless user experience**—Benefit from the same familiar Lync Server experience as Polycom CX desk phones

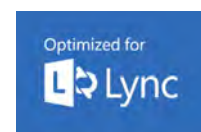

Product specifications

Audio—general

- Polycom® HD Voice™ (Polycom® Acoustic Clarity™ technology, mechanical design and wideband codec support)
- Individual volume settings with visual feedback for each audio path
- Voice activity detection
- Comfort noise fill
- DTMF tone generation/DTMF event RTP payload
- Low-delay audio packet transmission
- Adaptive jitter buffers
- Packet loss concealment
- Background noise suppression
- Cellular phone immunity
- Automatic gain control
- Dynamic noise reduction
- Acoustic echo cancellation

Audio—speaker/mic

- Speaker frequency response, 200–7 kHz
- Speaker volume, maximum at 1/2 meter peak volume: 85 dB
- Full-duplex speakerphone, compliant with IEEE 1329 Type 1
- Acoustic echo cancellation
- Mic frequency response: 150–7 kHz
- Mic pickup: 12 ft (3.5 m)

CODEC support

- Microsoft RTAudio
- G.722.1
- G.711 (narrowband, A-law and μ -law)

Power

- Built-in, auto-sensing IEEE 802.3af-2003 Power over Ethernet Class 3
- Optional AC power kit

User interface

- Display, 3.5", QVGA TFT 24-bit color graphical display, 320 x 240 pixels, with Unicode character capability
- LED backlight with adjustable brightness
- Backlight auto-dim when not in use

Accessibility

- High contrast UI graphic screen option (software)
- Compatible with commercially-available TTY adapter equipment

Buttons/keys

- 12-button dialpad, 0–9, *, #
- Volume up & volume down
- 2-way navigation: up, down, select, home, previous

- 2 soft keys + menu
- On/off hook
- Mute/unmute button

Indicators, LED

- Ringing/in call/mute/hold indicator (x 3)
- Presence Indicator

Connectivity

- Single ethernet 10/100 Base-T with RJ45 connector port
- IEEE 802.3af class single PoE ethernet 10/100 Base-T
- USB device port, Type B female
- 2 x extension Mic ports

Included accessories

- Ethernet cable, 25 ft (7.5 m)
- USB Cable, A–B (for “Better Together”), securable to device, 2 m

Accessories available separately

- AC Power Kit with 48V PSU, PoE Power Injector Cable and 2m line cord with local plug
- Extension mics, pair, with 10 ft (3 m) cables

Physical

- Weight
 - Console: 724 g
 - Packaged, with all included accessories: 1.852 kg
- Dimensions (L x W x H)
 - Phone: 365 x 324 x 67 mm
 - Packaged: 341 x 452 x 92 mm
- Security cable lock slot

Operating conditions

- Temperature: +32–104° F (0–+40° C)
- Relative humidity: +10–90% (non-condensing)

Storage temperature

- -40–+185° F (-40–+85° C)

Regulatory certifications

- Electrical safety
 - UL60950-1 (USA / Canada)
 - IEC/EN60950-1 (EU)
 - GOST(Russia)
 - KCC(Korea)
- EMC—general
 - CISPR22
- EMC—USA (Class B)
 - FCC Part 15
- EMC—Canada (Class B)
 - ICES00.3: 1998
- EMC—EU (Class B)
 - EN 55022
 - EN 55024

- EMC—ROW (Class B)
 - C & A Tick (Australia)
 - VCCI (Japan)
 - GOST (Russia)
 - KCC (Korea)
 - TRA (UAE)
 - Telepermit PTC220 (New Zealand)

Optimized for Microsoft® Lync®

- Microsoft® Lync® Server 2013
- Microsoft® Lync® Server 2010

Software features

- Basic mode
 - Contacts
 - Photos
 - Message waiting indicator
 - Standard Enterprise IP-PBX features, CAC, Survivability, E911 (US only), call park, etc.
 - Teleworker support
 - Conference leader experience
- Enhanced mode
 - Individual voice mail listings
 - Calendar
 - Join conference
 - “Better Together”
 - Lync integration call logs

Part number

- 2200-15810-025

Warranty

- 12 months

Polycom® CX3000 ships with

- Conference phone console
- 25ft Ethernet cable
- Captive USB cable
- Quickstart Guide
- Warranty Card

Need flexible financing?

Polycom **CAPITAL**
Collaborative Financing

www.polycom.com/polycom-capital

About Polycom

Polycom is the global leader in open standards-based unified communications and collaboration (UC&C) solutions for voice and video collaboration, trusted by more than 415,000 customers around the world. Polycom solutions are powered by the Polycom® RealPresence® Platform, comprehensive software infrastructure and rich APIs that interoperate with the broadest set of communication, business, mobile and cloud applications and devices to deliver secure face-to-face video collaboration in any environment.

Polycom, Inc.
1.800.POLYCOM
www.polycom.com

Polycom Asia Pacific Pte Ltd
+65 6389 9200
www.polycom.asia

Polycom EMEA
+44 (0)1753 723282
www.polycom.co.uk

