

VGA Extender Transmitter & Receiver

Extends transmission up to 100 meters

APPLICATION

Extend VGA video and audio signals up to 100 meters (328 ft) over a single Category cable for applications in classrooms, conference rooms, control centers, and public venues where reliable quality video is needed. Adjustable gain compensates for cable length to achieve superior video quality.



Transmitter — front



Transmitter — back



Receiver — front



Receiver — back

SPECIFICATION

VGA extender shall deliver screen resolutions of 1920 X 1200 @ 60Hz up to 30m (98 ft) and 1600 X 1200 up to 100m (328ft) over one Category cable. Shall support mono audio transmission. Shall provide adjustable gain for optimizing display quality, power, and link LED indicators, and hot-plugging for instant video output.

FEATURES

- Delivers screen resolutions of 1920 X 1200 @ 60Hz up to 30 m (98 ft) and 1600 X 1200 up to 100m (328ft) over one category-rated cable
- Supports mono audio transmission
- External power required only at receiver
- Supports hot-plugging devices for instant video output
- Adjustable gain for optimizing display quality over varying cable lengths
- Power and link LEDs aid in setup
- Ultra-compact transmitter and receiver modules – transmitter can be connected directly to source device

DESIGN CONSIDERATIONS

- Power required only at Rx end, USB cable included for connection to display USB port thereby eliminating need for AC power adapter

STANDARDS COMPLIANCE

FCC

PHYSICAL SPECIFICATIONS

Dimensions:	Tx & Rx
	35.3 mm W x 20.8 mm H x 58.7 mm D
	1.39" W x 0.82" H x 2.31" D
Materials:	Metal enclosures
Power input:	100 - 120VAC 50/60Hz 0.2A
Power output:	5VDC 1.0A
Temperature:	0°C to 50°C (32°F to 122°F)

COUNTRY OF ORIGIN

Taiwan

WARRANTY INFORMATION


For a copy of Leviton product warranties, visit www.leviton.com/warranty.

41910-V01

ELECTRONIC FILES


For CAD files, typical specs, or technical drawings (.DXF, .DWG), visit www.leviton.com.

Common configuration for VGA Extender

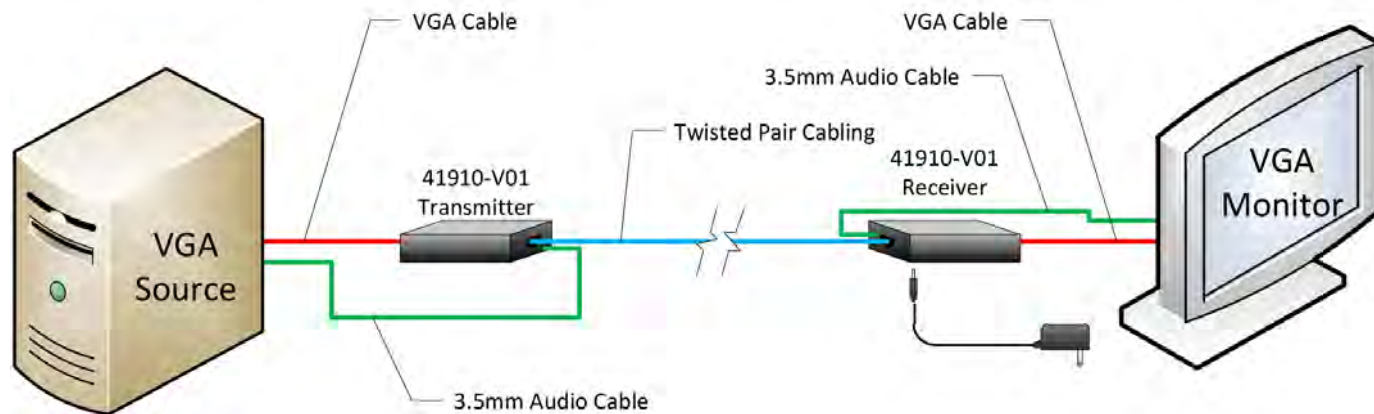


41910-V01

Transmitter

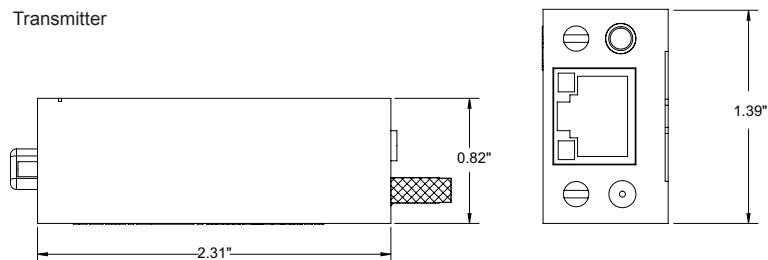

Receiver

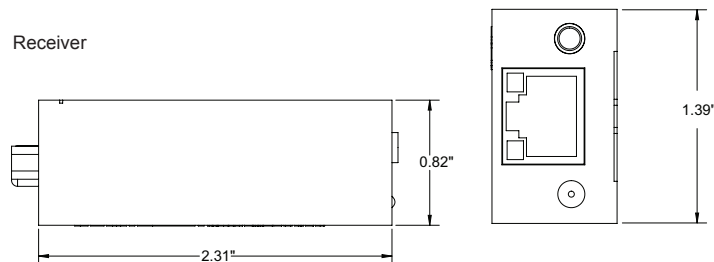

PART NUMBERS

Description

Part No.

VGA Extender Transmitter and Receiver, 100 m

41910-V01

Page 2 of 2

B15 5417



Leviton Network Solutions
2222 - 222nd St. SE
Bothell, WA 98021-4416

Asia / Pacific
T +1.631.812.6228
E infoasean@leviton.com

Canada
T +1.514.954.1840
E pcservice@leviton.com

Caribbean
T +1.954.593.1896
E infocaribbean@leviton.com

China
T +852.2774.9876
E infochina@leviton.com

Colombia
T +57.1.743.6045
E infocolombia@leviton.com

tel 1-800-824-3005
tel +1-425-486-2222
appeng@leviton.com
www.leviton.com

Europe
T +33.6.8869.1380
E infoeurope@leviton.com

India / SAARC
T +971.4.886.4722
E infoindia@leviton.com

Mexico
T +52.55.5082.1040
E lsamarketing@leviton.com

Middle East & Africa
T +971.4.886.4722
E lmeinfo@leviton.com

South Korea
T +82.2.3273.9963
E infokorea@leviton.com