


VGA over Cat5/Cat6 Extender Kit for 2 local and 2 remote displays, with EDID Copy, 1920x1440 at 60Hz

MODEL NUMBER: **B130-202**

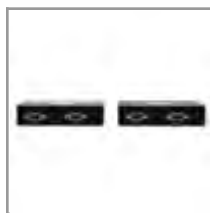

Description

Tripp Lite B130-202 allows you to extend two 1024x768 VGA video signals up to 500 ft., over ordinary Cat5e cable, from a single VGA source. The Transmitter / Receiver kit also features two local VGA HD15 ports, supporting a total of four VGA monitors (2 Local and 2 Remote). Compatibility issues can occur when EDID information is not properly communicated between the source and the display. The B130-202 includes an EDID copy feature which stores a monitor's EDID information in the transmitter and sends it to the source, ensuring optimal compatibility. Supports all operating systems, and is plug-and-play...no software or drivers required.

Features

- Connect up to four monitors; 2 local and 2 remote
- Extends a 1440 x 900 @ 60Hz signal up to 165 ft. (50 m) from the source
- Extends a 1024 x 768 @ 60Hz signal up to 500 ft. (150 m) from the source
- EDID copy feature ensures optimal display compatibility
- Built-in equalization control allows for adjustment of the video image
- All operating systems supported
- Plug-and-play; no software or drivers are required
- HDCP compliant

Specifications

OVERVIEW	
Chromebook Compatible	No
Display Style	Extender
Model Type	VGA
Cable Types	CAT5/CAT5E

Highlights

- Extends a VGA signal up to 500 ft.
- Connect up to four VGA monitors: 2 Local and 2 Remote
- EDID copy feature ensures optimal display compatibility

System Requirements

- PC with VGA video output
- Monitors with VGA input

Package Includes

- B130-202 Transmitter Unit
- B130-202 Receiver Unit
- (x2) external power supplies (Input: 100-240V, 50/60Hz, 0.5A Output: 5V, 2A)
- Screwdriver for equalization adjustment
- Owner's manual



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

PHYSICAL	
Shipping Weight (lbs.)	1.80
Unit Dimensions (hwd / in.)	Transmitter: 1.06 x 4.50 x 2.44 Receiver: 1.06 x 4.50 x 2.44
ENVIRONMENTAL	
Operating Temperature Range	32 to 122 F (0 to 50 C)
Storage Temperature Range	-4 to 158 (-20 to 70 C)
CONNECTIONS	
Connector A	HARDWIRE
Connector B	HARDWIRE
Local Console Ports	1 x RJ45, 3 x HD15F
Remote Console Port	1 x RJ45, 2 x HD15F
WARRANTY	
Product Warranty Period (Worldwide)	1-year limited warranty

© 2015 Tripp Lite. All rights reserved. All trademarks are the sole property of their respective owners. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Photos may differ slightly from final products.