


Quad Full-Motion Flex Arm Desk Clamp for 13" to 27" Flat-Screen Displays

MODEL NUMBER: DDR1327SQFC

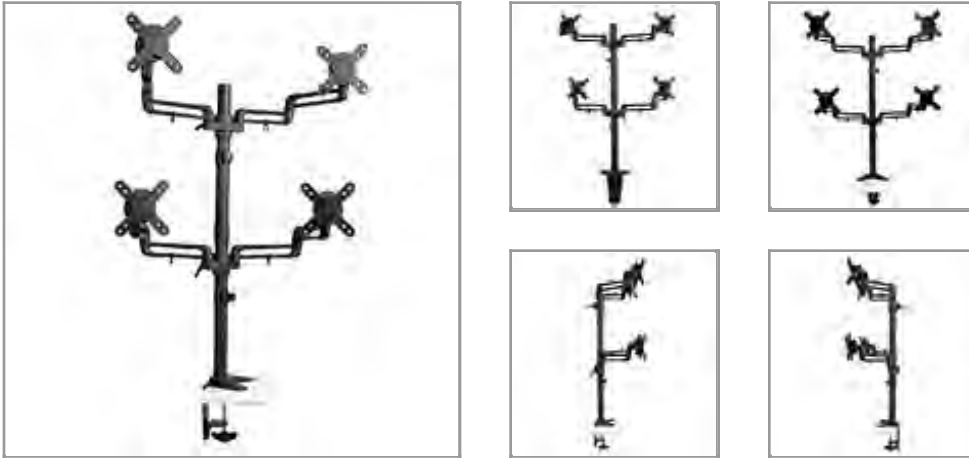

Highlights

- Increases available desk/table space in office workstation applications
- Quad mounts fit most flat-panel displays from 13" to 27"
- Convenient one-touch display adjustment for easy view optimization and improved ergonomics
- Wide range of motion with -15° to +15° tilt, 180° swivel and 360° rotation capability
- Each mount supports up to 22 lbs.
- 5-year warranty

Package Includes

- DDR1327SQFC Flex Arm Dual Flat-Screen Desk Clamp
- Mounting Hardware
- Owner's Manual

Description

Tripp Lite's VESA-compliant DDR1327SQFC Flex Arm Quad Desk Clamp frees up valuable space in your workstation. The unique flexible design offers an exceptional range of motion. Increase workday productivity with flexible arms that allow monitors to be placed back to back for use by more than one person. You can bring the screen closer with you need or move out of the way when you don't and space between the monitors is also fully adjustable. It features convenient one-touch display adjustment with tilt, swivel and rotation capabilities and fits most 13- to 27-inch flat-panel displays. Its durable, all-metal frame with scratch-resistant, powder-coat finish withstands the stress of repeated use and blends easily into any décor. It comes with all necessary mounting hardware, and each mount supports weights of up to 22 lbs. For peace of mind, the DDR1327SQFC comes backed by a 5-year warranty.

Features

- Tripp Lite's VESA-compliant DDR1327SQFC Flex Arm Quad Flat-Screen Desk Clamp frees up valuable space in your workstation and increases workday productivity with flexible arms that allow monitors to be placed back to back for use by more than one person.
- Unique flexible design offers an exceptional range of motion
- Convenient one-touch display adjustment with tilt, swivel and rotation capabilities and fits most 13- to 27-inch flat-panel displays
- Durable, all-metal frame with scratch-resistant, powder-coat finish withstands the stress of repeated use and blends easily into any décor
- Includes all necessary mounting hardware, and each mount supports weights of up to 22 lbs
- 5-year warranty

Specifications

| OVERVIEW | |
|-------------------|------------|
| Mounting Location | Desk Clamp |
| PHYSICAL | |



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

| | |
|---|--------------------------------------|
| Unit Dimensions (hwd / in.) | 34.65 x 33.62 x 4.53 |
| Unit Dimensions (hwd / cm) | 88.01 x 85.39 x 11.50 |
| Unit Weight (lbs.) | 13.4 |
| Unit Weight (kg) | 6.08 |
| Material of Construction | Steel |
| Color | Black |
| Monitor Display Size (in.) | 13 - 27 |
| Monitor Display Size (cm) | 33.02 - 68.58 |
| VESA Pattern (mm) | 75x75; 100x100 |
| Motion | Full |
| Degrees of Motion | -15/+15 Tilt; 180 swivel; 360 rotate |
| Maximum Weight Capacity (lbs.) | 22 |
| Maximum Weight Capacity (kg) | 9.98 |
| FEATURES & SPECIFICATIONS | |
| Tools Necessary | Yes |
| Cord Management | Yes |
| WARRANTY | |
| Product Warranty Period (U.S. & Canada) | 5-year limited warranty |

© 2015 Tripp Lite. All rights reserved. All trademarks are the sole property of their respective owners. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Photos may differ slightly from final products.