


SmartOnline 4U 16kVA 11.2kW UPS Spare/Replacement Power Module - for SU16000RT4U or SU16000RT4UHW

MODEL NUMBER: **SU16000RT4UPM**

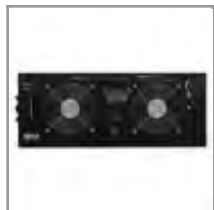

Highlights

- 16,000VA on-line 4U replacement power module
- Ideal for use as a spare or replacement power module for mission-critical UPS configurations involving SU16000RT4U or SU16000RT4UHW

Package Includes

- SU16000RT4UPM POWER MODULE ONLY (4U)

Description

16,000 VA (16kVA) on-line, double-conversion UPS replacement power module for UPS configurations involving SU16000RT4U or SU16000RT4UHW

Features

- 16,000VA on-line 4U replacement power module
- Ideal for use as a spare or replacement power module for mission-critical UPS configurations involving SU16000RT4U or SU16000RT4UHW
- REPLACEMENT POWER MODULE ONLY

Specifications

OVERVIEW	
Model Type	Módulos de Energía
Accessories Type	Power Module
OUTPUT	
Output Volt Amp Capacity (VA)	16000
Output kVA Capacity (kVA)	12
Output Watt Capacity (Watts)	11200
Crest Factor	3:1
Frequency Compatibility	50 / 60 Hz
Output AC Waveform (AC Mode)	Sine wave



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

Output AC Waveform (Battery Mode)	Onda sinusoidal pura
PHYSICAL	
Primary Form Factor	Rack
UPS Power Module Dimensions (hwd, in.)	7 x 17.5 x 34
UPS Power Module Dimensions (hwd, cm)	17.8 x 44.4 x 86.4
UPS Power Module Weight (lbs.)	86
UPS Power Module Weight (kg)	39
UPS Dimensions Details	4U power module component only.
UPS Shipping Dimensions (hwd / in.)	13 x 17.5 x 34
UPS Shipping Dimensions (hwd / cm)	33 x 44.5 x 86.4
Shipping Weight (lbs.)	134.4
Shipping Weight (kg)	61
UPS Housing Material	Steel
COMMUNICATIONS	
Communications Interface	DB9 Serial; Cierre de contacto; EPO (apagado de emergencia); Ranura para interfaz SNMP/Web
CERTIFICATIONS	
UPS Certifications	Probado conforme a UL1778 (EE. UU.); Probado conforme a CSA (Canadá); Cumple con FCC Parte 15 Clase A (EMI); ROHS (Restricción de Sustancias Peligrosas)
WARRANTY	
Product Warranty Period (Worldwide)	garantía limitada de 2 años

© 2015 Tripp Lite. All rights reserved. All trademarks are the sole property of their respective owners. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Photos may differ slightly from final products.