

RFM SERIES KITTED SERVER CABINET



R. F. Mote Series Server Kitted Cabinets available 30" and 24" Wide. Standard kitted Server cabinets include: 2 Perforated doors, 2 side panels, 2 pair cage-nut style mounting rails, levelling feet, cover plates, and hardware package.


Each cabinet may be configured with a wide variety of options such as: power bars, ground bars, fan assemblies, chimney ducts, air stops, brush kits, cable troughs, vertical and horizontal cable mangers, shelves, electronic door locks, and perforated side panels. Optional accessories can be factory installed in configurations best suited to their end use, or ordered separately and installed by the customer.

Standard Features:

- Lockable perforated Front and Rear doors
- Doors: Electronic and Combination lock options available
- 2 Solid, lockable, lift off side panels
- 2 Pair Mounting angles, punched to 19" EIA universal spacing for cage nuts
- 4 Grounding points
 - 2 in top (#10-32 x 1/2" stud)
 - 2 in base (1/4-20 x 1/2" stud)
- Top c/w cable access openings (cover plates provided)
- Hardware package (qty 24, 1/4-20 Cage nuts and screws)
- Adjustable levelling feet
- Durable textured powder coated finish
- Standard colour is all black
- Custom colours and sizes available upon request

Highlights:

- Heavy gauge steel
- All welded construction
- Provisions for fans and cable access
- Cabinet doors are field reversible; hinge kit req'd
- Load capacity : up to 2500 lbs

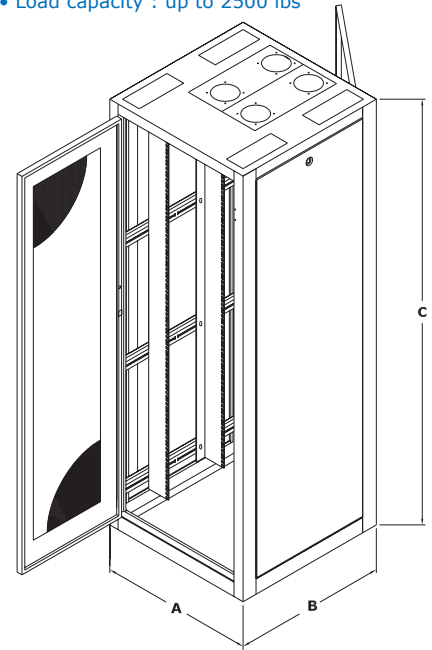

Ganging version available. Shipped less the side panels and c/w ganging kit - add suffix '-G' to part number. e.g. RFM-304283-US-19-B-G

30" Wide Cabinet — 19" EIA Mount

PART NUMBER	A	B	C	#of U's
RFM-304890-US-19-B	30.150	48.150	90.00	48U
RFM-304883-US-19-B	30.150	48.150	83.00	44U
RFM-304290-US-19-B	30.150	42.150	90.00	48U
RFM-304283-US-19-B	30.150	42.150	83.00	44U
RFM-304272-US-19-B	30.150	42.150	72.00	38U
RFM-304259-US-19-B	30.150	42.150	59.00	30U
RFM-304235-US-19-B	30.150	42.150	35.00	17U
RFM-303690-US-19-B	30.150	36.150	90.00	48U
RFM-303683-US-19-B	30.150	36.150	83.00	44U
RFM-303672-US-19-B	30.150	36.150	72.00	38U
RFM-303659-US-19-B	30.150	36.150	59.00	30U
RFM-303635-US-19-B	30.150	36.150	35.00	17U
RFM-303090-US-19-B	30.150	30.150	90.00	48U
RFM-303083-US-19-B	30.150	30.150	83.00	44U
RFM-303072-US-19-B	30.150	30.150	72.00	38U
RFM-303059-US-19-B	30.150	30.150	59.00	30U
RFM-303035-US-19-B	30.150	30.150	35.00	17U

24" Wide Cabinet — 19" EIA Mount

PART NUMBER	A	B	C	#of U's
RFM-244890-US-19-B	24.00	48.150	90.00	48U
RFM-244883-US-19-B	24.00	48.150	83.00	44U
RFM-244290-US-19-B	24.00	42.150	90.00	48U
RFM-244283-US-19-B	24.00	42.150	83.00	44U
RFM-244272-US-19-B	24.00	42.150	72.00	38U
RFM-244259-US-19-B	24.00	42.150	59.00	30U
RFM-244235-US-19-B	24.00	42.150	35.00	17U
RFM-243690-US-19-B	24.00	36.150	90.00	48U
RFM-243683-US-19-B	24.00	36.150	83.00	44U
RFM-243672-US-19-B	24.00	36.150	72.00	38U
RFM-243659-US-19-B	24.00	36.150	59.00	30U
RFM-243635-US-19-B	24.00	36.150	35.00	17U
RFM-243090-US-19-B	24.00	30.150	90.00	48U
RFM-243083-US-19-B	24.00	30.150	83.00	44U
RFM-243072-US-19-B	24.00	30.150	72.00	38U
RFM-243059-US-19-B	24.00	30.150	59.00	30U
RFM-243035-US-19-B	24.00	30.150	35.00	17U

Note: 23" and 24" EIA mount also available for 30" wide cabinet