

SPLIT DOORS: PERFORATED, ACRYLIC, & SOLID




Features:

- Heavy gauge steel
- All welded construction
- Both cabinet doors lift off for ease of equipment and cable installation
- Equipped with 3-Point locking swing handle
- Electronic and Combination lock options available
- Durable textured powder coated finish
- Standard colour is all black
- Custom colours and sizes available upon request

Highlights:

- Smoked acrylic allows for easy viewing of equipment without opening the door
- Perforated doors provide optimal air flow

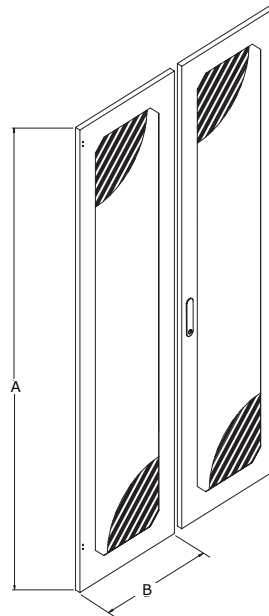

30" wide RFM Series cabinets, 83" height

DESCRIPTION	PART NUMBER	A	B
PERFORATED	RFM-3083-1-P-DD	77.68	13.15
SMOKED ACRYLIC	RFM-3083-1-DD	77.68	13.15
SOLID	RFM-3083-2-DD	77.68	13.15

24" wide RFM Series cabinets, 83" height

DESCRIPTION	PART NUMBER	A	B
PERFORATED	RFM-2483-1-P-DD	77.68	10.00
SMOKED ACRYLIC	RFM-2483-1-DD	77.68	10.00
SOLID	RFM-2483-2-DD	77.68	10.00

30" wide RFM Series cabinets, 72" height

DESCRIPTION	PART NUMBER	A	B
PERFORATED	RFM-3072-1-P-DD	66.68	13.15
SMOKED ACRYLIC	RFM-3072-1-DD	66.68	13.15
SOLID	RFM-3072-2-DD	66.68	13.15

24" wide RFM Series cabinets, 72" height

DESCRIPTION	PART NUMBER	A	B
PERFORATED	RFM-2472-1-P-DD	66.68	10.00
SMOKED ACRYLIC	RFM-2472-1-DD	66.68	10.00
SOLID	RFM-2472-2-DD	66.68	10.00

30" wide RFM Series cabinets, 59" height

DESCRIPTION	PART NUMBER	A	B
PERFORATED	RFM-3059-1-P-DD	53.68	13.15
SMOKED ACRYLIC	RFM-3059-1-DD	53.68	13.15
SOLID	RFM-3059-2-DD	53.68	13.15

24" wide RFM Series cabinets, 59" height

DESCRIPTION	PART NUMBER	A	B
PERFORATED	RFM-2459-1-P-DD	53.68	10.00
SMOKED ACRYLIC	RFM-2459-1-DD	53.68	10.00
SOLID	RFM-2459-2-DD	53.68	10.00