


## MOUNTING ANGLES / STANDARD EIA RAILS

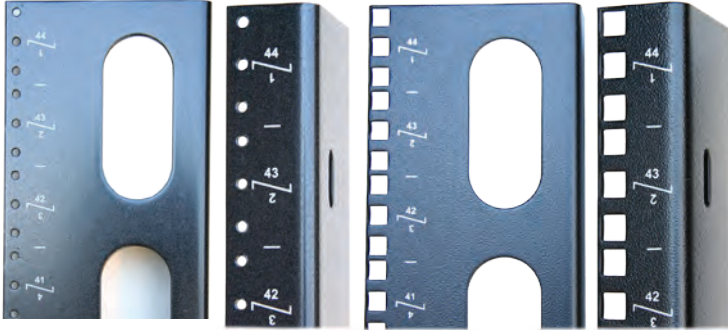

### Features:

- 11 gauge steel
- Silk screened 'U' Markings
- EIA rails are used to mount patch panels, servers, rack mount accessories, etc.
- Available tapped #10-32
- Also available with .375" x .375" square holes for cage nut mounting
- Wet painted, durable finish to avoid clogged threads in tapped rails
- Standard colour is all black with white silk screened markings


### Highlights:

- 30" Wide cabinet version c/w cable pass through access holes

### 30" wide RFM Series cabinets

	PART NUMBER		A	B	# of U's
	TAPPED #10-32	CAGE-NUT STYLE			
19" EIA MOUNT	RFM-1990-MA	RFM-1990-MA-SQ	84.00	4.45	48U
	RFM-1983-MA	RFM-1983-MA-SQ	77.00	4.45	44U
	RFM-1972-MA	RFM-1972-MA-SQ	66.50	4.45	38U
	RFM-1959-MA	RFM-1959-MA-SQ	52.50	4.45	30U
	RFM-1935-MA	RFM-1935-MA-SQ	29.75	4.45	17U
23" EIA MOUNT	RFM-2383-MA	RFM-2383-MA-SQ	77.00	2.45	44U
	RFM-2372-MA	RFM-2372-MA-SQ	66.50	2.45	38U
	RFM-2359-MA	RFM-2359-MA-SQ	52.50	2.45	30U
	RFM-2335-MA	RFM-2335-MA-SQ	29.75	2.45	17U

EIA standard pattern

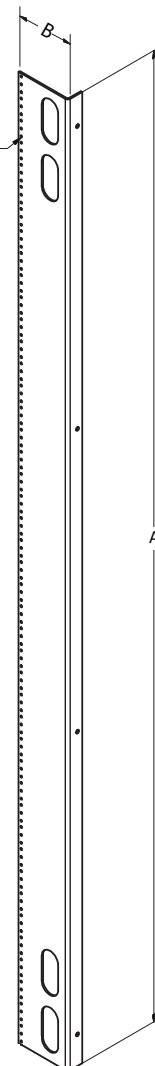

### 24" wide RFM Series cabinets

	PART NUMBER		A	B	# of U's
	TAPPED #10-32	CAGE-NUT STYLE			
19" EIA MOUNT	RFM-1990-MA-24	RFM-1990-MA-24-SQ	84.00	1.38	48U
	RFM-1983-MA-24	RFM-1983-MA-24-SQ	77.00	1.38	44U
	RFM-1972-MA-24	RFM-1972-MA-24-SQ	66.50	1.38	38U
	RFM-1959-MA-24	RFM-1959-MA-24-SQ	52.50	1.38	30U
	RFM-1935-MA-24	RFM-1935-MA-24-SQ	29.75	1.38	17U