

## LOW PROFILE WALL MOUNT CABINETS




### Standard Features:

- Heavy gauge steel
- Low profile design and vertical racking, provides 26" depth
- 19" EIA standard
- Rack rails pivot out, from the top or from the bottom of the body, to allow easy access to equipment
- Cable access openings and multiple lacing points provided
- Provision in bottom for cooling fan
- Vented lockable door
- Multiple knockouts accommodate 1" And 1.25" Conduit (provided in top, bottom, and sides)
- Durable textured powder coated finish
- Standard colour is all black
- Custom colours and sizes available upon request

### Highlights:

- Optional 2u patch panel mounting brackets available. (Provides an additional 2u mounting)  
P/N# RFM-LP-2U-BRKT

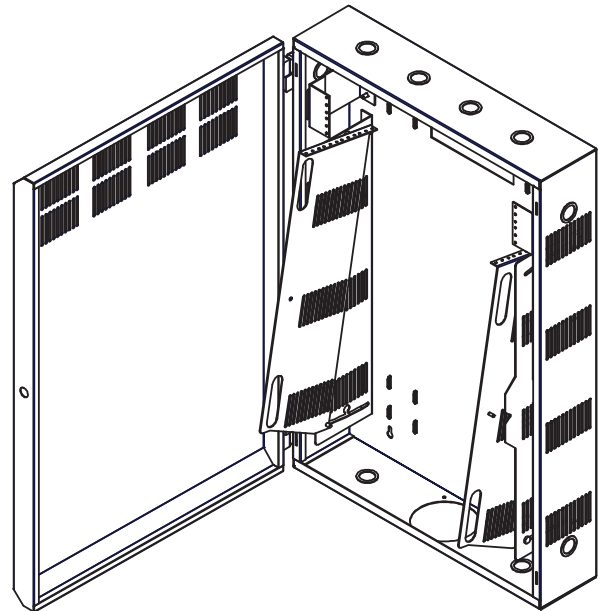

### LOW PROFILE WALLMOUNT CABINET

PART NUMBER	A	#of U's
RFM-2436-WM-LP-4U	7.50	4U
RFM-2436-WM-LP-6U	11.00	6U

### 2U PATCH PANEL MOUNTING BRACKET

PART NUMBER	#of U's	FITS WITH P/N
RFM-LP-2U-BRKT	2U	RFM-2436-WM-LP-4U RFM-2436-WM-LP-6U

