
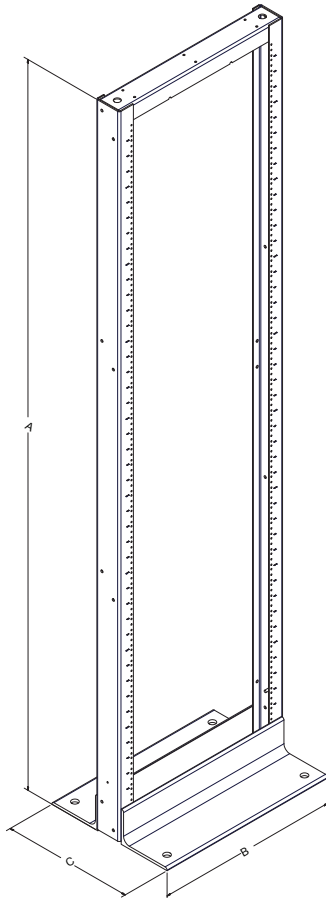


## TWO POST RACK

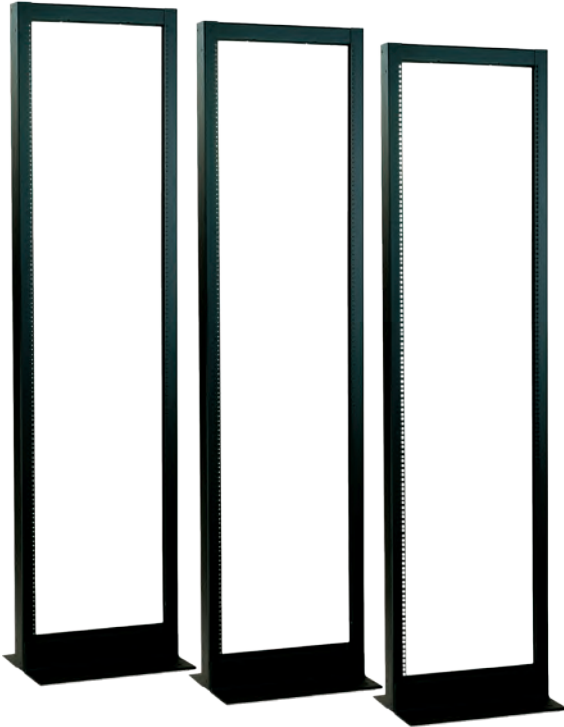

### Features:

- 11 gauge steel frame
- Structural steel floor angles, 5/16" thick, c/w holes to bolt to floor
- Various heights available: 24U / 38U / 44U / 48U
- Stamped 'U' markings
- 19", 23" and 24" mounting available
- Load capacity : 2000 lbs
- c/w 1 integrated ground stud 1/4-20 thread x 3/4" length
- c/w (2x) 0.750" DIA holes in top
- All welded construction

### Highlights:

- Tapped Rack: Holes tapped #10-32 UNF to EIA standard
- Wet painted black to avoid clogged threads
- Cage-Nut Rack: 0.375" X 0.375" Square holes for cage nuts and server rails
- Optionally available as bolt-together units
- Vertical CMS option (see Pages 4.1.5 & 4.1.6)
- Optional heavy duty kits increase footprint to 36"
- Custom sizes available on request

Tapped #10-32					
	PART NUMBER	A	B	C	# of U's
19" EIA MOUNT	RFM-1924-RB	48.00	21.50	15.00	24U
	RFM-1938-RB	72.50	21.50	15.00	38U
	RFM-1944-RB	83.00	21.50	15.00	44U
	RFM-1948-RB	90.00	21.50	15.00	48U
23" EIA MOUNT	RFM-2324-RB	48.00	25.50	15.00	24U
	RFM-2338-RB	72.50	25.50	15.00	38U
	RFM-2344-RB	83.00	25.50	15.00	44U
	RFM-2348-RB	90.00	25.50	15.00	48U

Cage nut style					
	PART NUMBER	A	B	C	# of U's
19" EIA MOUNT	RFM-1924-RB-SQ	48.00	21.50	15.00	24U
	RFM-1938-RB-SQ	72.50	21.50	15.00	38U
	RFM-1944-RB-SQ	83.00	21.50	15.00	44U
	RFM-1948-RB-SQ	90.00	21.50	15.00	48U

Hardware package included (qty 24 cage-nuts and screws)

Tapped both sides					
	PART NUMBER	A	B	C	# of U's
19" EIA MOUNT	RFM-1944-RB-TBS	83.00	21.50	15.00	44U
	RFM-1948-RB-TBS	90.00	21.50	15.00	48U
23" EIA MOUNT	RFM-2344-RB-TBS	83.00	25.50	15.00	44U

Both front and back of rack tapped #10-32