

## RACK SHELF: 2 POINT RACK MOUNTING

### Front mount, Centre mount, and Retractable / Sliding



Front mount  
(100LB load capacity)



Centre mount, double-sided  
(200LB load capacity)



Retractable / sliding  
(100LB load capacity)

#### Features:

- Heavy gauge steel
- 19" Rack mount shelf fits RFM Series Cabinets and Racks
- 2-point rack mounting
- Perforated for ventilation, mounting servers, cable ties, and accessories
- Durable textured powder coated finish
- Standard colour is all black

#### Highlights:

- All -RRS series shelves feature heavy duty full extension drawer slides
- All -RRS series shelves feature return bends for added strength

Front mount - fixed series - 100LB capacity					
	PART NUMBER	A	B	C	# of U's
19" EIA MOUNT	RFM-1915-RFS	17.50	15.00	3.50	2U
	RFM-1921-RFS	17.50	21.00	3.50	2U
	RFM-1912-RFS	17.50	12.00	3.50	2U
	RFM-1909-RFS	17.50	9.00	3.50	2U


Note: 23" mount available on request

Centre mount - fixed series - 200LB capacity					
	PART NUMBER	A	B	C	# of U's
19" EIA MOUNT	RFM-1920-DRFS	17.50	20.00	8.50	2U
	RFM-1928-DRFS	17.50	28.00	12.50	2U


Note: 23" mount available on request

Front mount - retractable series - 100LB capacity				
	PART NUMBER	A	B	# of U's
19" MOUNT	RFM-1920-RRS	16.50	20.00	2U


Note: 23" mount available on request

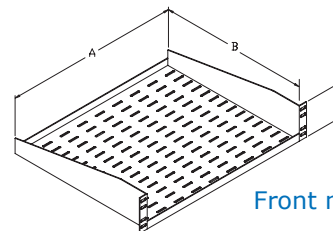

Front mount - fixed

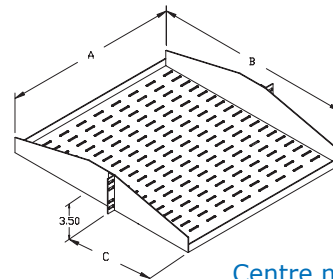

Centre mount, double sided

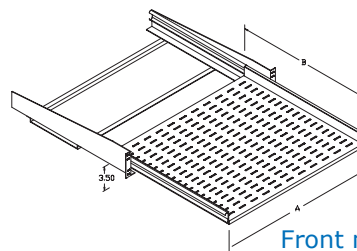

Front mount, retractable