




# Ty-Rap

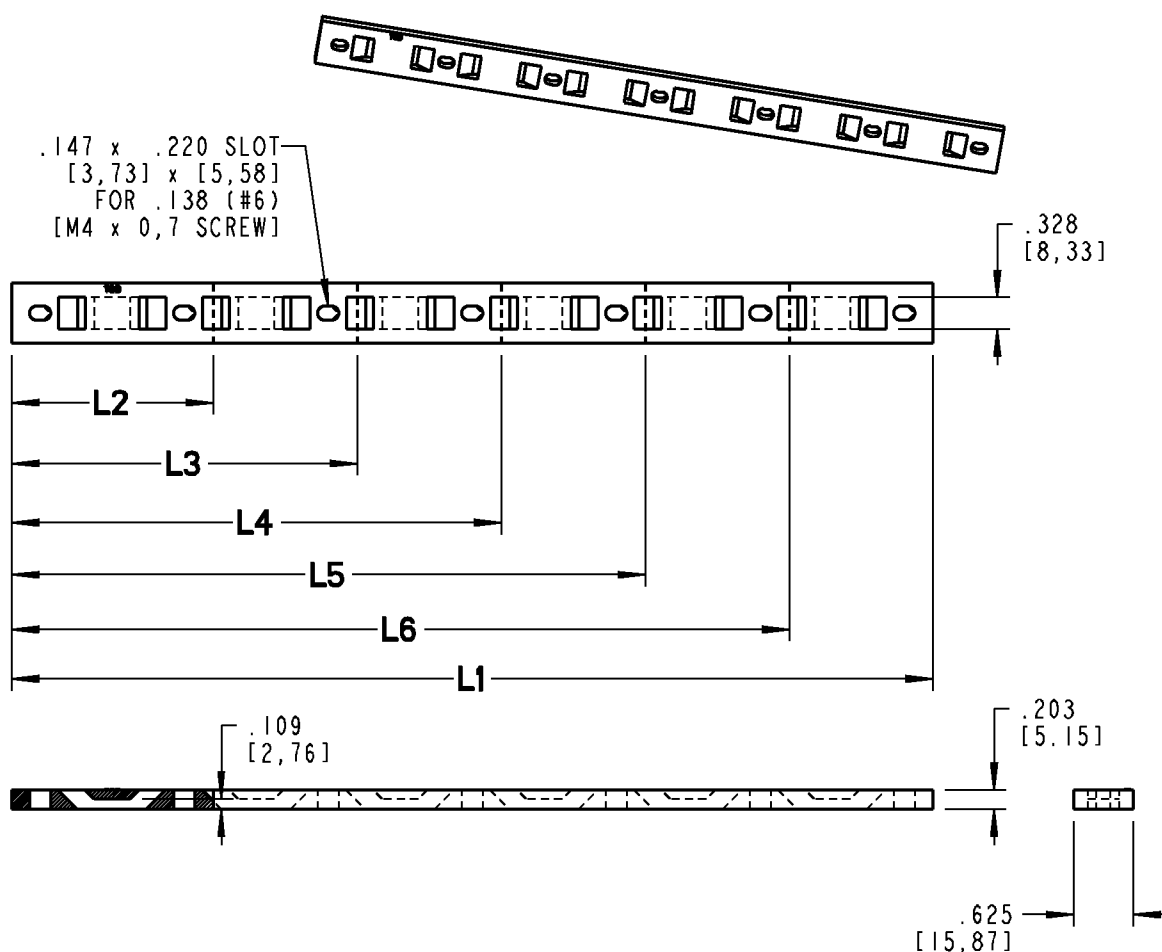

#### NOTES:

1. MATERIAL: NYLON 6,6- COLOR: NATURAL
2. FLAMMABILITY: UL94V-2
3. OPERATING TEMPERATURE RANGE: -40°F [-40°C] TO 185°F [85°C]
4. STANDARD PACKAGE QUANTITY: 100

| CATALOG NUMBER | MAXIMUM TIE WIDTH | CAPACITY (BUNDLES) | ( L ) LENGTH          | MIL STANDARD PART NO. |
|----------------|-------------------|--------------------|-----------------------|-----------------------|
| TC1112         | .301 [7,64]       | 6                  | ( L1 ) 9.952 [252,78] | MS3339-11             |
| TC1113         |                   | 1                  | ( L2 ) 2.100 [53,34]  | MS3339-6              |
| TC1114         |                   | 2                  | ( L3 ) 3.600 [91,44]  | MS3339-7              |
| TC1115         |                   | 3                  | ( L4 ) 5.100 [129,54] | MS3339-8              |
| TC1116         |                   | 4                  | ( L5 ) 6.600 [167,64] | MS3339-9              |
| TC1117         |                   | 5                  | ( L6 ) 8.100 [205,74] | MS3339-10             |

#### GENERAL NOTES

1. ALL DIMENSIONS ARE FOR REFERENCE ONLY.
2. DIMENSIONS IN BRACKETS [ ] ARE IN METRIC UNITS.

#### REVISIONS

SEE ERN ( \*\*\*\* )  
FOR APPROVAL SIGNATURES  
& RELEASE DATE.  
PROJECT NO: \*\*\*\*

**Thomas & Betts**  
www.tnb.com

DESCRIPTION: **MULTIPLE BUNDLE MOUNTING STRIP**

ORIGINAL PROJECT NO / ( ERN NO )

FM401183 / ( 2007645 )

SHEET NO:

1 OF 1

REV. NO:

-

DRAWING NO:

WSD-000329