

SMT-4032

40" LED Monitor




Key Features

- Support up to 1,920 x 1,080 resolution
- High contrast ratio 5000 : 1
- Fast response time 8ms
- HDMI, DVI, VGA, and Component (CVBS Common) video input
- Ethernet / RS-232C remote control
- Magicinfo player S2 : Auto play function

Dimensions

Unit : mm (inch)

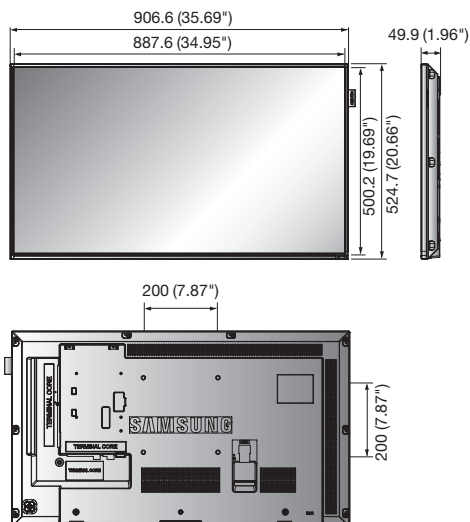

		SMT-4032
DISPLAY		
Type	LED	
Screen Size	40"	
Max. Resolution	1,920 x 1,080	
Brightness	350cd/m ²	
Contrast Ratio	5,000 : 1	
Aspect Ratio	16 : 9	
Viewing Angle (H/V)	178° / 178°	
Display Color	16.7million	
Response Time	8ms (G to G)	
Video System	NTSC / PAL	
Panel Life	50,000hours	
Filter Type	3D combfilter	
INTERFACE		
Video	Connector	VGA, DVI, HDMI, Component (CVBS common)
	Connector	Analogue D-sub (15 pin), DVI-D
	Input Signal	0.7Vpp ±5%
RGB / DVI	Available Format	640 x 480@60Hz/66Hz/72Hz/75Hz (VGA), 720 x 400@70Hz, 800 x 600@56Hz/60Hz/72Hz/75Hz (SVGA), 832 x 624@75Hz, 1,024 x 768@60Hz/70Hz/75Hz (XGA), 1,152 x 864@75Hz, 1,280 x 720@60Hz, 1,280 x 800@60Hz, 1,280 x 1,024@60Hz/75Hz (SXGA), 1,360 x 768@60Hz, 1,440 x 900@60Hz, 1,600 x 900@60Hz, 1,680 x 1,050@60Hz, 1,920 x 1,080@60Hz
HDMI	Connector	HDMI
	Available Format	640 x 480p@60Hz, 720 x 480i@60Hz, 720 x 480p@60Hz, 720 x 576i@50Hz, 720 x 576p@50Hz, 1,280 x 720p@50Hz/60Hz, 1,920 x 1,080i@50Hz/60Hz, 1,920 x 1,080p@50Hz/60Hz
Audio	Connector	Stereo mini jack
	Output Signal	Loop-through line level (PC only), Speakers : 10W x 2
Application Support		Remote controller
ON SCREEN DISPLAY		
Functions		VESA™ DPM compatible
Language		Chinese (Traditional/Simplified), English, French, German, Italian, Japanese, Korean, Polish, Portuguese, Russian, Spanish, Swedish, Turkish
GENERAL		
Electrical	Input Voltage	100 ~ 240V AC (±10%) (50/60Hz)
	Power Consumption	Max. 121W
Environmental	Operating Temperature	0 ~ +40°C (+32°F ~ +104°F)
	Operating Humidity	10% ~ 80% (Non-condensing)
Mechanical	Dimensions with Stand (WxHxD)	925.4 x 612.6 x 311.0mm (36.43" x 24.12" x 12.24")
	Dimensions without Stand (WxHxD)	906.6 x 524.7 x 49.9mm (35.69" x 20.66" x 1.96")
	Bezel Size	Top 9.5mm (0.37") / Bottom 15.0mm (0.59")
	Weight	7.5Kg (16.54 lb)
	Cabinet Color	Black
	Rack Mounts	Optional
	VESA Mounts Interface	200 x 200mm
Accessory	BNC Input Cable (Gender)	RCA to BNC cable
	Foot Stand	SBM-3240ST (Optional)

* The latest product information / specification can be found at www.samsungsecurity.com

Optional Accessory



Foot Stand SBM-3240ST