

ProxCARD[®] II Card

Durable, Value Priced Proximity Access Card

Features:

- Offers universal compatibility with all HID proximity readers.
- Provides durable packaging and consistent read range.
- Provides an external number for easy identification and control.
- Supports formats up to 85 bits, with over 137 billion codes.
- Custom pre-printed artwork available.
- A PVC overlay allows for on-site photo ID using most direct image printers.
- Using HID's ProxProgrammer[®], card vendors can ship ProxCARD II proximity cards, custom programmed to their customers' requirements, from their own inventory. Enables smaller order quantities and overnight delivery. (Check with vendor for availability.)

THE RF-PROGRAMMABLE PROXCARD[®] II PROXIMITY ACCESS CARD IS THE INDUSTRY CHOICE FOR A COST-EFFECTIVE SOLUTION TO PROXIMITY ACCESS CONTROL.

- **Proven, Reliable Technology** – Offers extremely consistent read range. Unaffected by body shielding or variable environmental conditions, even when close to keys and coins.
- **Convenient To Use** – Can fit into a wallet or purse. Use with a strap and clip as a photo ID badge.
- **Cross-reference** – A cross-reference list correlating the external card number and the programmed ID number is provided for easy system administration.
- **Security** – Offers over 137 billion unique codes.
- **Long Life** – Passive, no-battery design allows for an infinite number of reads.
- **Durability** – Strong, flexible and resistant to cracking and breaking.
- **Companion Products**– 1321 Photo pouch overlay
1324 PVC Direct print overlay


The RF-programmable ProxCARD[®] II proximity access card is the industry choice for a cost-effective solution to proximity access control.

SPECIFICATIONS

ProxCards® II Card

Base Part Number	1326
Typical Maximum* Read Range	ProxPoint® Plus reader-up to 3" (7.5 cm) MiniProx® reader-up to 5.5" (14 cm) ThinLine® II reader-up to 5.5" (14 cm) ProxPro® reader-up to 8" (20 cm) ProxPro® II reader-up to 9" (22.9 cm) Prox80™-up to 5.5" (14 cm) MaxiProx® reader-up to 24" (60 cm)
Dimensions	2.135" x 3.385" x 0.075" MAX. (5.4 x 8.6 x 0.19 cm)
Operating Temperature	-50° to 160° F (-45° to 70° C)
Options	External card numbering (inkjet only; no laser engraving) Custom artwork (text or graphics)
Weight	0.24 oz. (6.8 gm)
Warranty	Lifetime

NOTES:
*Dependent on local installation conditions.

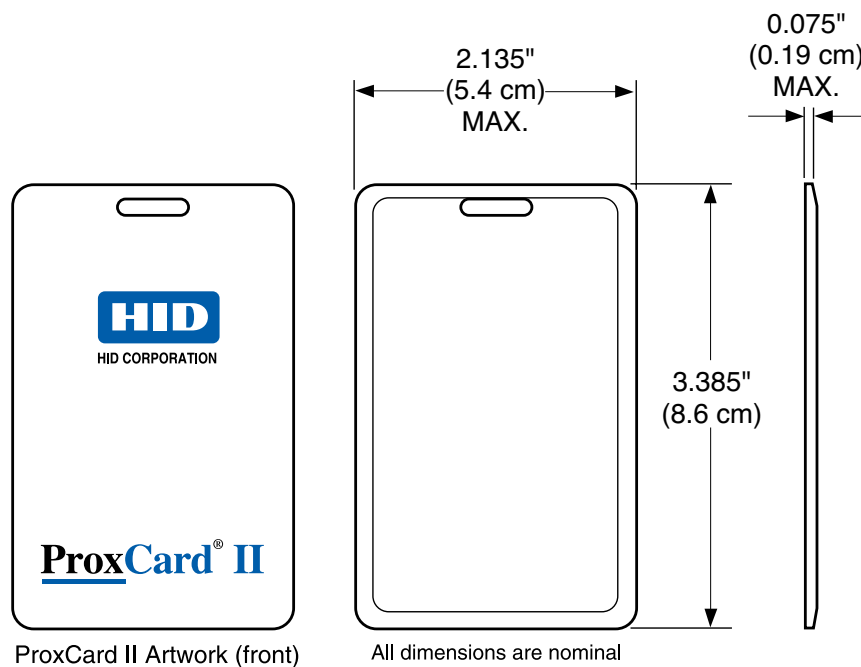

North America: +1 949 732 2000
 Toll Free: 1 800 237 7769
 Europe, Middle East, Africa: +44 1440 714 850
 Asia Pacific: +852 3160 9800
 Latin America: +52 55 5081 1650

ASSA ABLOY
 An ASSA ABLOY Group brand

© 2011 HID Global Corporation. All rights reserved. HID, the HID logo, ProxCards logo are trademarks or registered trademarks of HID Global in the U.S. and/or other countries. All other trademarks, service marks and product or service names are trademarks or registered trademarks of their respective owners.
 2012-05-14-hid-proxcardsii-cards-ds-en