

800-960 MHz Yagi Antenna (14 dBi)



Model Numbers

- CSI-AY/806-960/14

Frequency Range


- 806-960 MHz

Features & Benefits


- 14 dBi Gain
- Hermetically Sealed Driven
- Rugged Lightweight Design
- Symmetric Construction
- Stainless Steel Hardware



Radiation Patterns

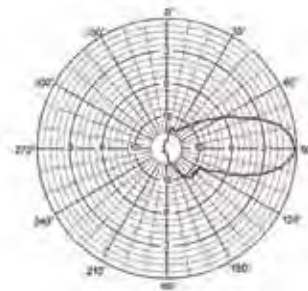

Horizontal

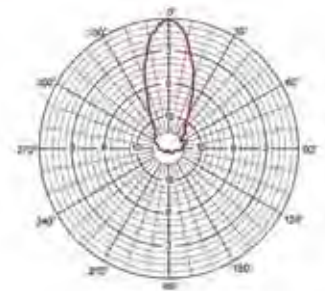

Vertical

Electrical Specifications

Horizontal Beamwidth	35° +/- 5°
Vertical Beamwidth	30° +/- 5°
Gain	14 dBi
Polarization	Vertical/Horizontal
VSWR	<1.5:1
Max Input Power	100 Watts
Lightning Protection	Direct Ground

Mechanical Specifications

Dimensions	2.2 x 7.3 x 45 in.
Weight	1.43 lbs.
Connectors	N-Female
Standard Mounting Style	Stainless Steel
Rated Wind Speed	134 mph
Included Mounting Hardware fits 1.18-2.36 inch OD Pipe	

Specifications subject to change without notice.

