



NEXTSPEED® Category 6 Patch Panels

Ports	Height Inches (mm)	Width Inches (mm)	Rack Units	Color	Catalog No.
24	1.75" (45)	19" (483)	1	Black	P6E24U
48	3.50" (89)	19" (483)	2	Black	P6E48U
96	7.00" (178)	19" (483)	4	Black	P6E96U
24	1.75" (45)	19" (483)	1	White	P6E24UW
48	3.50" (89)	19" (483)	2	White	P6E48UW
96	7.00" (178)	19" (483)	4	White	P6E96UW



P6E48U Front



 
P6E48U Rear



P624AU



P648AU



NEXTSPEED® Category 6 Angled Patch Panels

Ports	Height Inches (mm)	Width Inches (mm)	Rack Units	Color	Catalog No.
24	1.75" (45)	19" (483)	1	Black	P624AU
48	3.50" (89)	19" (483)	2	Black	P648AU

Note: HP6Axx angled panel protrudes 4.46" from the plane of the rack. Hubbell recommends one (1) extra inch of space between the door and panel angle.

MUTOA, Category 6 Component

Description	Catalog No.
12-port, Category 6, MUTOA, universal, 89D	P612U



P612U

1-Punch Termination Tool


Description	Catalog No.
Patch panel tool with head and blades	TX4PP
Patch panel tool replacement head (includes blades)	TX4PPH
Patch panel tool replacement blades	TX4PPBL



TX4PP

Rear Cable Management Bars

Description	Type	Catalog No.
Cable management bar and screws	19" Rack Mount	CMBR
Cable management bar, 4" bracket and screws	HPW Panel Mount	PCMBR4
Cable management bar, 6" bracket and screws	HPW Panel Mount	PCMBR6
Cable management bar, straight, with screws	19" Rack Mount	ECMBRS
Cable management bar, 3" with screws	19" Rack Mount	ECMBR3
Cable management bar, 6" with screws	19" Rack Mount	ECMBR6

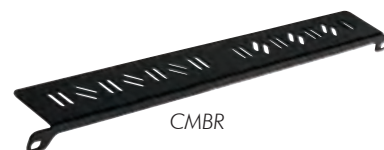

CMBR



PCMBR4