


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

TWIST TIE

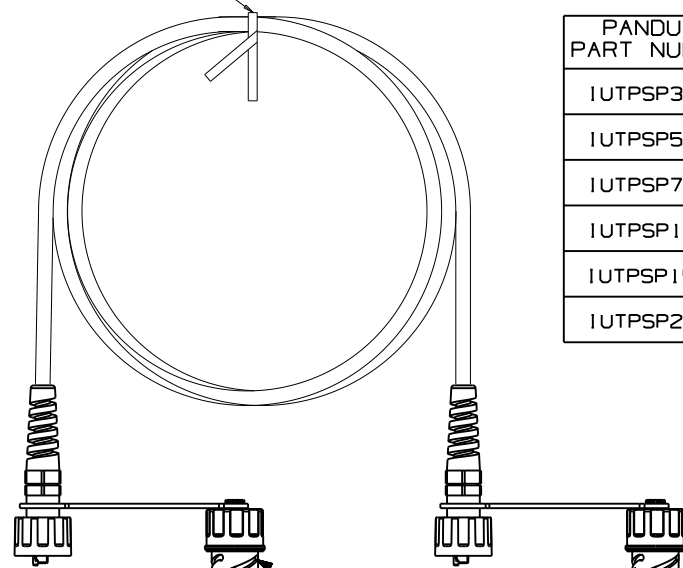

WITH PLUG CAPS

PANDUIT PART NUMBER	MIN. CABLE LENGTH	WEIGHT
IUTPSP3BL	3 FT.	1.97 lbs/10 PCS (735.3 g/10 PCS)
IUTPSP5BL	5 FT.	2.53 lbs/10 PCS (944.3 g/10 PCS)
IUTPSP7BL	7 FT.	3.09 lbs/10 PCS (1153.3 g/10 PCS)
IUTPSP10BL	10 FT.	3.93 lbs/10 PCS (1784.2 g/10 PCS)
IUTPSP15BL	15 FT.	5.31 lbs/10 PCS (1981.9 g/10 PCS)
IUTPSP20BL	20 FT.	6.70 lbs/10 PCS (2500.7 g/10 PCS)

NOTES:

- SEE CURRENT CATALOG FOR VARIOUS APPLICATIONS AND TO INDICATE COLOR AND OR PACKAGE QUANTITY.
- SEE CATALOG FOR A COMPLETE LIST OF PARTS APPLICABLE FOR USE WITH THIS PART.
- DIMENSIONS IN PARENTHESES ARE IN METRIC.
- CABLE MEETS CATEGORY 6 REQUIREMENTS.
- ALL MATERIALS AND COMPONENTS USED MUST MEET THE MATERIAL RESTRICTIONS OR RoHS, (EUROPEAN DIRECTIVE 2002/95/EC ON THE RESTRICTION OF HAZARDOUS SUBSTANCES) AS PROPOSED BY THE RoHS TECHNICAL ADAPTATION COMMITTEE.

WITHOUT PLUG CAPS

PANDUIT PART NUMBER	MIN. CABLE LENGTH	WEIGHT
IUTPSPNC3BL	3 FT.	1.53 lbs/10 PCS (692.84 g/10 PCS)
IUTPSPNC5BL	5 FT.	1.99 lbs/10 PCS (901.84 g/10 PCS)
IUTPSPNC7BL	7 FT.	2.45 lbs/10 PCS (1110.84 g/10 PCS)
IUTPSPNC10BL	10 FT.	3.84 lbs/10 PCS (1741.74 g/10 PCS)
IUTPSPNC15BL	15 FT.	4.28 lbs/10 PCS (1939.41 g/10 PCS)
IUTPSPNC20BL	20 FT.	5.42 lbs/10 PCS (2458.24 g/10 PCS)

T568B WIRING

PLUG POSITION

1
2
3
4
5
6
7
8

CABLE WIRE
WHITE ORANGE
ORANGE
WHITE GREEN
BLUE
WHITE BLUE
GREEN
WHITE BROWN
BROWN

PLUG CAPS - ON IUTPSP*BL PARTS ONLY

MODEL FILENAME		SIZE
DRAWING FILENAME		A
M024790C_DC391/00A		
CATEGORY 6 INDUSTRIALNET, UTP, STRANDED, PATCH CORDS WITH AND WITHOUT PANDUIT PLUG CAPS CUSTOMER DRAWING		
PANDUIT [®] TINLEY PARK, IL 60487		I.I. NUMBER
		PRODUCT SPEC/ PKG SPEC
		ASSY METHOD/ TEST METHOD
		SCALE
		NONE
DRAWN BY BJN		PART NO. IUTPSP*BL IUTPSPNC*BL
DATE 3-14-11		DRAWING NO. 02479-391
CHK'D MBVE		

R	3-14-11	BJN	MBVE	RELEASED TO PRODUCTION	02479-391	RDE			
REV	DATE	BY	CHK	DESCRIPTION	ECN	R	CUST	SUP	OTH