



Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	2 AWG
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	15/16 in.
Stud Size	1/4 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	BROWN
Panduit Die Index No. on Barrel	P33
Alternate Industry Die Index No. () on Barrel	(10)

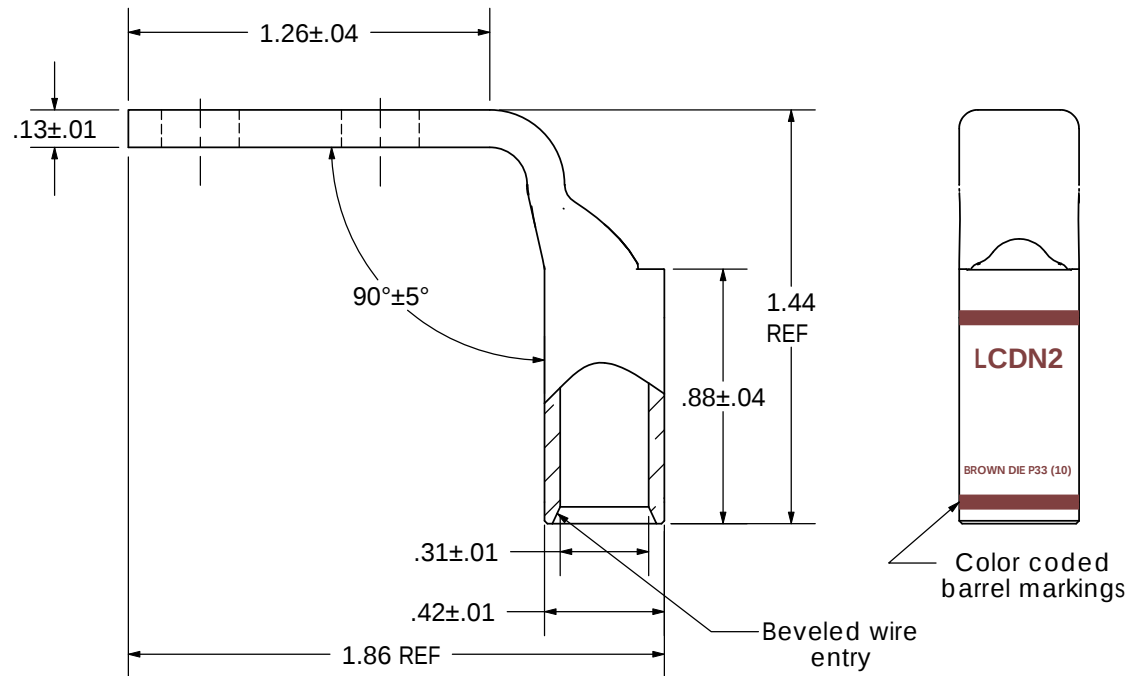

LISTED
Wire Connector

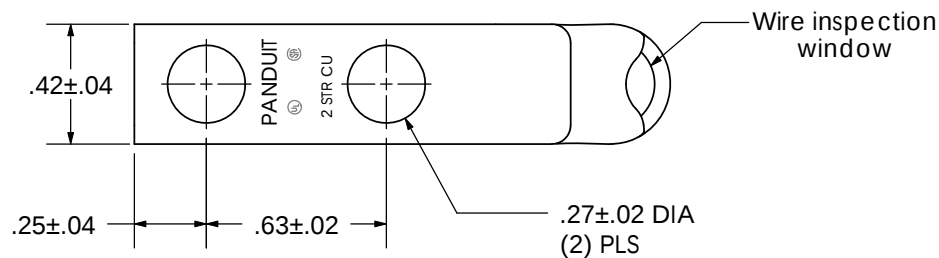

						 PANDUIT CORP. TINLEY PARK, ILLINOIS	
						LCDN2-14AF-Q Copper Lug - Two-Hole Narrow Tongue, Standard Barrel, 90° Angle Tongue	
02	1/11	JHNU	JHNU	REVISED OVERALL HEIGHT: WAS 1.38 REVISED TONGUE THICKNESS: WAS .11			
REV	DATE	BY	CHK	DESCRIPTION	ECN	SCALE N/A	DRAWING NO / CAD FILE LCDN2-14AF-CUST