


Intensifier H® Series Indoor/Outdoor Bullet Camera

See Color In Almost Complete Darkness Without IR LEDs

HTINTB8H	2.8 - 12mm auto iris varifocal lens, dark grey housing
HTINTB8HW	2.8 - 12mm auto iris varifocal lens, white housing
HTINTB9H	5-50mm auto iris varifocal lens, dark grey housing
HTINTB9HW	5-50mm auto iris varifocal lens, white housing
HTINTB10H	9-22mm auto iris varifocal lens, dark grey housing
HTINTB10HW	9-22mm auto iris varifocal lens, white housing

Features

- 1/3" Sony Super HAD™ CCD
- 700 lines of color resolution
- Amplify existing light with no distance limitations
- No problems caused by objects that reflect or absorb IR light sources
- Minimum illumination 0.00002 lux (Intensify @ 512x)
- Now with presets: Outdoor, Indoor, Elevator, Lobby, Hallway & Dark
- 12VDC / 24VAC dual voltage operation
- Full OSD operation
- External controls for zoom & focus
- S/N Ratio more than 52dB (weight on)
- EZ mount system simplifies installation
- Relay outputs for motion detection
- Weather resistant operation
- IP66 compliant
- Anti-moisture glass and circuitry eliminates fog or condensation under any weather condition
- 5 year warranty

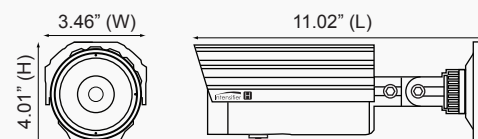

Specifications

Image Sensor	1/3" Sony Super HAD™ CCD
Resolution	700 TV lines
Minimum Illumination	CDS off: 0.15 lux CDS on: 0.00002 lux
Effective Pixels	976 (H) x 494 (V)
Total Pixels	1020 (H) x 508 (V)
TV System	NTSC
Scanning Frequency	15.734kHz (H) & 59.94Hz (V)
Scanning System	2:1 interlace
Synchronization	Internal
S/N Ratio	More than 52dB
Video Output	CVBS: 1.0Vp-p / 75 ohms
Electronic Shutter Speed	1/60 sec. – 1/120,000 sec.
OSD	Available
DWDR	On / Off (level adjustable)
Backlight Compensation	BLC / HLC / Off
Day/Night	Color / BW / Auto / Ext
AGC	High / Low / Off

White Balance	ATW / Outdoor / Indoor / Manual / AWC (1,700°K – 11,000°K)
Intensify	Auto / Off (selectable 2x – 512x)
Motion Detection	On / Off (8 programmable zones)
Privacy Masking	On / Off (12 programmable zones)
Speco DNR	On / Off (level adjustable)
Digital Zoom	On / Off (1x - 16x)
DIS	On / Off
Sharpness	On / Off (level adjustable)
Flip / Mirror	On / Off
Power Consumption	12VDC, 400mA / 24VAC, 170mA
Power Supply	12VDC / 24VAC dual voltage operation (power supply not included)
Operating Temperature	-4° F – 140° F
Dimensions	3.46" (W) x 4.01" (H) x 11.02" (L)
Weight	3 lbs.

Speco Technologies is constantly developing and improving products. We reserve the right to modify product design and specifications without notice and without incurring any obligation. Rev. 11/7/14



Optional Accessories



INTJBS
Square
Junction Box



INTCM
Corner/Pole
Adaptor



CVCJBB
Round
Junction Box



PSW4
24VAC
Power Supply



PSW5
12VDC
Power Supply