



NEXTSPEED® Ascent Category 6A Patch Panels

Ports	Height Inches (mm)	Width Inches (mm)	Rack Units	Color	Catalog No.
24	1.75" (45)	19" (483)	1	Black	HP6A24U
48	3.50" (89)	19" (483)	2	Black	HP6A48U
96	7.00" (178)	19" (483)	4	Black	HP6A96U
24	1.75" (45)	19" (483)	1	Silver	HP6A24US
48	3.50" (89)	19" (483)	2	Silver	HP6A48US
96	7.00" (178)	19" (483)	4	Silver	HP6A96US



 
HP6A24U



HP6A48U



HP6A48AU



NEXTSPEED® Ascent Category 6A Angled Patch Panels

Ports	Height Inches (mm)	Width Inches (mm)	Rack Units	Color	Catalog No.
24	1.75" (45)	19" (483)	1	Black	HP6A24AU
48	3.50" (89)	19" (483)	2	Black	HP6A48AU

Note: HP6Axx angled panel protrudes 4.46" from the plane of the rack. Hubbell recommends one (1) extra inch of space between the door and panel angle.

MUTOA, Category 6A

Description	Catalog No.
12-port, Category 6A, MUTOA, universal, 89D	HP6A12U



HP6A12U

1-Punch Termination Tool


Description	Catalog No.
Patch panel tool with head and blades	TX4PP
Patch panel tool replacement head (includes blades)	TX4PPH
Patch panel tool replacement blades	TX4PPBL



TX4PP

Rear Cable Management Bars

Description	Type	Catalog No.
Cable management bar and screws	19" Rack Mount	CMBR
Cable management bar, 4" bracket and screws	HPW Panel Mount	PCMBR4
Cable management bar, 6" bracket and screws	HPW Panel Mount	PCMBR6
Cable management bar, straight, with screws	19" Rack Mount	ECMBRS
Cable management bar, 3" with screws	19" Rack Mount	ECMBR3
Cable management bar, 6" with screws	19" Rack Mount	ECMBR6

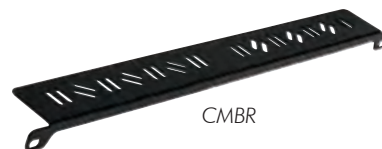

CMBR



PCMBR4