


50/125 Multimode Pigtail, 12-fiber, 900 µm, SC-PC, 1 meter

OR-P1TF4ZRFZZZ001M

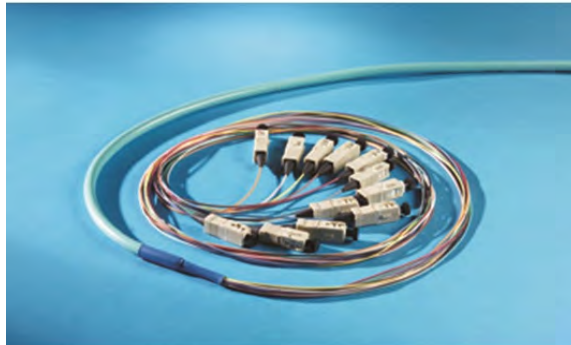

50/125 Multimode Pigtail, 12-fiber, 900µm, SC-PC, 1 meter. Former product number: OR-626TF4ZR-FZ001M

features & benefits

- **All common fiber types offered:** Provides industry leading performance and assures compliance to common industry standards.
- **Industry leading guarantee of 0.50 dB or better (versus TIA/EIA 568B.3 requirement of 0.75 dB):** Supports robust low loss fiber optic transmission in structured cabling systems.
- **100% visual inspection:** Ensures that all polished surfaces are free from defects.
- **100% Insertion Loss testing, test report included:** Ensures low loss connections.

specifications

General Info

Cable Type: Pigtails
Typical Applications: Multimode

Dimensions

Length Metric: 1

Cord Information

Connector Type End One: SC-PC
Connector Type End Two: Unterminated
Finish End One: Physical Contact-PC
Finish End Two: Physical Contact-PC

Jacket Rating: UL OFNR Riser
Max Insertion Loss: 0.50 dB
Max Return Loss: < - 20 dB
Min Bend Radius: 25 mm (1")

Technical Information

Fiber Capacity: 12
Performance Rating: Multimode 50125
Equipment Type: Patch Cord