


MIGHTY MO 20 VERTICAL MANAGERS

Patch Cord Capacities

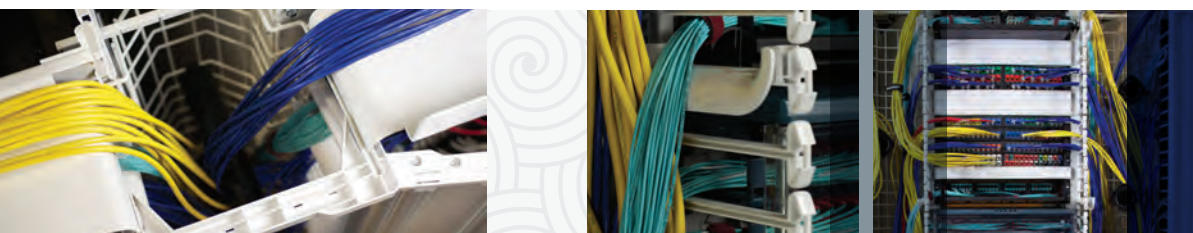

PART NO.	DESCRIPTION	USEABLE AREA (SQUARE INCH)	CABLE O.D. (IN)	RECOMMENDED FILL (40%)			MAXIMUM FILL (60%)		
				Cat 5e	Cat 6	Cat 6a	Cat 5e	Cat 6	Cat 6a
				0.215	0.230	0.290	0.215	0.230	0.290
Mighty Mo® 20 Vertical Manager with Door									
MM20VMD706-X	6.5"W x 10.25"D for 7' MM20 racks	35		420	350	245	595	525	350
MM20VMD710-X	10.5"W x 15"D for 7' MM20 racks	91		1092	910	637	1547	1365	910
MM20VMD712-X	12.25"W x 15"D for 7' MM20 racks	112		1344	1120	784	1904	1680	1120
MM20VMD716-X	16.25"W x 15"D for 7' MM20 racks	164		1968	1640	1148	2788	2460	1640
MM20VMD806-X	6.5"W x 10.25"D for 8' MM20 racks	35		420	350	245	595	525	350
MM20VMD810-X	10.5"W x 15"D for 8' MM20 racks	91		1092	910	637	1547	1365	910
MM20VMD812-X	12.25"W x 15"D for 8' MM20 racks	112		1344	1120	784	1904	1680	1120
MM20VMD816-X	16.25"W x 15"D for 8' MM20 racks	164		1968	1640	1148	2788	2460	1640
MM20VMD906-X	6.5"W x 10.25"D for 9' MM20 racks	35		420	350	245	595	525	350
MM20VMD910-X	10.5"W x 15"D for 9' MM20 racks	91		1092	910	637	1547	1365	910
MM20VMD912-X	12.25"W x 15"D for 9' MM20 racks	112		1344	1120	784	1904	1680	1120
Mighty Mo 20 Vertical Manager with Split Covers									
MM20VMS704-X	4"W X 8.6"D for 7' MM20 racks	21		252	210	147	357	315	210
MM20VMS706-X	6"W X 8.6"D for 7' MM20 racks	35		420	350	245	595	525	350
MM20VMS710-X	10"W X 13.6"D for 7' MM20 racks	63		756	630	441	1071	945	630
MM20VMS804-X	4"W X 8.6"D for 8' MM20 racks	21		252	210	147	357	315	210
MM20VMS806-X	6"W X 8.6"D for 8' MM20 racks	35		420	350	245	595	525	350
MM20VMS810-X	10"W X 13.6"D for 8' MM20 racks	63		756	630	441	1071	945	630
MM20VMS904-X	4"W X 8.6"D for 9' MM20 racks	21		252	210	147	357	315	210
MM20VMS906-X	6"W X 8.6"D for 9' MM20 racks	35		420	350	245	595	525	350
MM20VMS910-X	10"W X 13.6"D for 9' MM20 racks	63		756	630	441	1071	945	630
Mighty Mo 20 Vertical Manager Cage with Latches									
MM20VML704-X	4"W X 6"D for 7' MM20 racks	16		192	160	112	272	240	160
MM20VML706-X	6"W X 6"D for 7' MM20 racks	26		312	260	182	442	390	260
MM20VML804-X	4"W X 6"D for 8' MM20 racks	16		192	160	112	272	240	160
MM20VML806-X	6"W X 6"D for 8' MM20 racks	26		312	260	182	442	390	260



MIGHTY MO 20

MIGHTY MO 20 CHANNEL RACKS

Horizontal Cable Capacities



PART NO.	DESCRIPTION	USEABLE AREA (SQUARE INCH)	24 CNT	SINGLE CHANNEL CAPACITY			TOTAL RACK CAPACITY		
			CABLE	Cat 5e	Cat 6	Cat 6a	Cat 5e	Cat 6	Cat 6a
			O.D. (IN)	1.125"	1.25"	1.625"	1.125"	1.25"	1.625"
Mighty Mo® 20 Channel Rack									
MM20706-X	6.5"D, for 7' MM20 racks	34		288	240	156	576	480	312
MM20710-X	10.50"D, for 7' MM20 racks	56		480	288	240	960	576	480
MM20716-X	16.25"D, for 7' MM20 racks	88		768	480	336	1536	960	672
MM20724-X	24"D, for 7' MM20 racks	130		1080	744	516	2160	1488	1032
MM20730-X	30"D, for 7' MM20 racks	164		1344	960	648	2688	1920	1296
MM20810-X	10.50"D, for 8' MM20 racks	56		480	288	240	960	576	480
MM20816-X	16.25"D, for 8' MM20 racks	88		768	480	336	1536	960	672
MM20824-X	24"D, for 8' MM20 racks	130		1080	744	516	2160	1488	1032
MM20830-X	30"D, for 8' MM20 racks	164		1344	960	648	2688	1920	1296
MM20916-X	16.25"D, for 9' MM20 racks	88		768	480	336	1536	960	672
MM20924-X	24"D, for 9' MM20 racks	130		1080	744	516	2160	1488	1032
MM20930-X	30"D, for 9' MM20 racks	164		1344	960	648	2688	1920	1296

©2014 Legrand All Rights Reserved rev.6/14 MM20-FILL

designed to be better.™



Data Communications

125 Eugene O'Neill Drive
New London, CT 06320
800.934.5432
www.legrand.us

570 Applewood Crescent
Vaughan, Ontario L4K 4B4
905.738.9195
www.legrand.ca

Follow Us

