

FLUSH SWING HANDLES



Flush Handles are optional for any solid, window or disconnect door that includes 3-point latching, except Voice/Data and Colocation cabinets. They are ergonomically designed to provide style and function in a low profile. The handle is die-cast zinc finished with RAL 9005 textured black polyester powder paint. Provision to add your logo is included. Handle can be installed to rotate either clockwise or counterclockwise.

Handle with Screwdriver Defeater

Enclosure security is provided by the integrated tool-to-open feature that releases the handle when rotated, allowing access to the enclosure.

Handle with Keylock

Keylock feature locks the handle to provide security for the enclosure. When the key is in the unlocked position, the pushbutton releases the handle to provide access to the enclosure. Two keys are furnished.

Handle for Padlock

Padlocking Handle provides security when using up to a 5/16 padlock. Pushbutton releases the handle to provide access to the enclosure.

Handle with DIN Profile Provision

DIN Flush Handle is provided with the option to add your DIN profile lock or to accept Hoffman DIN profile lock PDKL (order separately).

BULLETIN: P20

Catalog Number	Description
PFHDF	Flush Handle with Defeater
PFHKBL	Keylocking Flush Handle
PFHPBL	Padlocking Flush Handle
PFHDBL	DIN Profile Flush Handle

FLUSH BEZELS



Bezel with Insert

Can be used on any solid, window or disconnect door when a low-profile, tool-to-open operating mechanism is needed. Bezel is RAL 9005 textured black plastic. Provision to add your logo is included. Flush bezels are provided with screwdriver slot insert. Other key inserts are available to fit the flush bezel (order separately).

Small Bezel with Insert

Can be used in place of the small Flush Swing Handle when a low-profile, tool-to-open operating mechanism is needed. Bezel is RAL 9005 textured black plastic. Provision to add your logo is included. Small flush bezels are furnished with a screwdriver slot insert. Other key inserts are available to fit the small flush bezel (order separately).

BULLETIN: P20, P20S

Catalog Number	Description
PFBS	Flush Bezel with insert
PSFBS	Small Flush Bezel with Insert
PFBSSS	Large Flush Bezel with Stainless Steel Insert

L HANDLE



The L Handle is a stylish option for any solid, window or disconnect door, except Voice/Data or Colocation cabinets. It can be installed to rotate either clockwise or counterclockwise. Handle comes with a bezel, includes keylocking provision and is finished with RAL 9005 textured black polyester powder paint. Two keys are included. The bezel permits your logo to be inserted.

BULLETIN: P20

Catalog Number	Description
PLHK	L Handle with 2 keys and logo slot, key code 333

SMALL FLUSH SWING HANDLE A-T-O



Swing Handles are used on smaller doors (doors 1000 mm and less in height that have two-point latching). Handles are ergonomically designed to provide style and function in a low profile. They can be installed to rotate either clockwise or counterclockwise. The shape of the design provides aesthetic compatibility with the Flush Swing Handles. This handle includes keylocking provision, two keys, provision to add your logo and is furnished in RAL 9005 textured black polyester powder paint.

BULLETIN: P20

Catalog Number	Description
PSHKB	One handle and two keys

KEY INSERTS A-T-O



Key Inserts are used with Flush Bezels. Optional for any solid, window and disconnect door. Key Inserts are zinc die-cast. A matching key is included.

BULLETIN: P20, P20S

Catalog Number	Description
PKOTM7	7-mm triangle
PKOTM8	8-mm triangle
PKOTM65	CNOMO
PKOSM7	7-mm square
PKOSM8	8-mm square
PKOGBK3	Double-bit with 3-mm pin
PKOGBK3SS	Double-bit insert

PADLOCK KIT



The kit adds a padlocking capability to any of the Flush Swing Handles (except for Small Flush Swing Handle). Field modification of the flush handle is required. Includes a stainless steel locking post that will accommodate up to a 5/16-in. padlock shackle.

BULLETIN: P20

Catalog Number	Description
PFHPK	Padlock Kit

DIN LOCK INSERTS (FOR DIN PROFILE HANDLE ONLY)



The DIN profile keylock provides keylocking security for the Flush Swing Handle with DIN provision. Includes profile lock and two keys. Order one profile lock for each handle.

DIN Lock Kit for PROLINE™ DataCom doors includes two locks keyed alike with one of 100 different key codes and two keys (master key available).

All DIN Lock Inserts are zinc die-cast.

BULLETIN: DPY, P20

Catalog Number	Description
PKOSLFH	Slotted insert profile cylinder
PKOTM7FH	7-mm triangle insert profile cylinder
PKOSM7FH	7-mm square insert profile cylinder
PKOTM8FH	8-mm triangle insert profile cylinder
PKOGBK3FH	Double-bit 3-mm insert profile cylinder
PDKL	DIN keylock, 2 keys included, key code 333
PDKLRKPR	DIN Lock Kit for PROLINE DataCom doors

DIN profile inserts are used with DIN flush swing handles. One key is included (except for slotted insert).

FOLDING SHELF



The shelf mounts to door using the Door Bar Grid Straps (sold separately). Shelf is 16 gauge steel with 12 gauge brackets. Shelf finish is RAL 7035 textured light-gray polyester powder paint. Locks in two positions—90 degrees as a shelf and 15 degrees as a writing surface. Also mounts to three-row grid straps, side or back panel, or any flat surface. Holds up to 30 pounds.

BULLETIN: P20

Catalog Number	Description
PSHDM	Fits door widths 600, 700, 800 and 1000 mm

DOOR BAR GRID STRAPS



Straps mount to the door bar. Used to mount accessories to the door. Constructed of 16 gauge steel with plated finish. Holds up to 100 lb.

BULLETIN: P20

Catalog Number	Description
PGH1S4D	Fits 400-mm wide door
PGH1S5D	Fits 500-mm wide door
PGH1S6D	Fits 600-mm wide door
PGH1S7D	Fits 700-mm wide door
PGH1S8D	Fits 800-mm wide door
PGH1S10D	Fits 1000-mm wide door

180-DEGREE HINGE KIT



Optional hinging for steel solid, window or disconnect doors. The 180-degree hinges provide a door opening up to 260-degrees on single-bay enclosures. These hinges mount to the door flange and have a low-profile appearance. The kit includes three hinges with textured black polyester powder paint and all necessary mounting hardware. Cannot be used on PROLINE™ FLOTEK™ or CONNECTEK™ front doors.

BULLETIN: P20

Catalog Number	Description
PH180	180-Degree Hinge Kit

DOOR STOP KIT



The Door Stop Kit holds doors open at 130 degrees. The kit includes a slotted bracket that mounts to either the top or bottom of the door and a stop arm that attaches to the frame. The Door Stop Kit is plated, mounts without drilling and includes all necessary mounting hardware. Not suitable for use with 180-degree hinging. Drill points in window door brackets for mounting Door Stop Kit.

BULLETIN: P20

Catalog Number	Description
PDSK	Door Stop Kit

DOOR SUPPORT ROLLER KIT



The Door Support Roller Kit supports and aligns heavy doors. Kit is suitable for all solid doors and glass window doors. Kit is not recommended for use on solid doors with door bars removed or polycarbonate window doors. Drill points in window door brackets for mounting Door Stop Kit.

BULLETIN: P20


Catalog Number	Description
PDSRKL	Door Support Roller Kit

THERMOPLASTIC DATA POCKET



Provides a convenient place to store wiring diagrams, operation manuals and other documentation inside the enclosure. Adhesive-backed pockets mount inside the solid enclosure cover. Mounting hardware included. Thermoplastic pockets are dark gray and have cut-away areas for easy inspection of contents.

BULLETIN: UX1Y

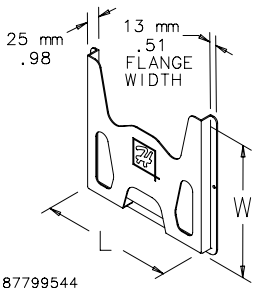

Catalog Number	Description	Size L x W in./mm
ADP1	Small pocket	6.00 x 6.00 152 x 152
ADP2	Large pocket	12.00 x 12.00 305 x 305

STEEL DATA POCKET

Steel Data Pocket fastens to the bottom of the door. Finish is RAL 7035 textured light-gray polyester powder paint. Door Bar Grid Straps (purchased separately) must be used to change the vertical mounting position of the Data Pocket.

BULLETIN: P20

Catalog Number	AxBxC in./mm	Description
PDP1	16.46 x 8.82 x 2.83 418 x 224 x 72	Single size fits all door widths

