

## PROLINE™ GOLD SERIES COMPUTER WORKSTATION, TYPE 12



### INDUSTRY STANDARDS

UL 508A Listed; Type 12; File Number E61997  
cUL Listed per CSA C22.2 No 94; Type 12; File No. E61997

NEMA/EEMAC Type 12  
IEC 60529, IP55

### APPLICATION

The PROLINE™ Gold Series Computer Workstation is a full-featured, off-the-shelf solution for protecting PC computer systems. Made with sturdy unibody construction, the enclosure accommodates a complete range of accessories.

### SPECIFICATIONS

- 14 gauge steel body
- 14 and 16 gauge steel doors and covers
- Seams continuously welded and ground smooth
- Seamless foam-in-place gasket on all doors and covers
- Smoke gray 0.25-in.-thick polycarbonate window on upper front door
- Quarter-turn latches on upper front door for 1400-mm high cabinets
- PROLINE latching system and keylocking swing door handles on upper front door for 1600- and 1800-mm high cabinets
- Solid lower front and full rear doors with keylocking swing door handles
- Internal rails facilitate mounting of PROLINE internal components
- Options include solid upper front door and solid front and rear covers with screw fasteners
- Full rear opening provides maximum mounting space and easy access to interior components
- Optional partial subpanel
- Hinges on bottom for 1400-mm enclosures
- Solid centerpost on front for 1200-mm enclosures

### FINISH

Cabinet finish is RAL 7035 textured light-gray polyester powder paint. Keyboard door finish is RAL 9005 textured black polyester powder paint.

### ACCESSORIES

See also *Accessories*.



Caster Kit  
Industrial Corrosion Inhibitors  
Thermoplastic Data Pocket  
Electric Heater  
Compact Cooling Fans  
Grid Straps  
Flush Swing Handles  
Key Inserts  
180-Degree Hinge Kit  
Perforated Panels  
19-in. Rack Angles

### BULLETIN: P10

### Standard Product Computer Workstation, Type 12

| Catalog Number | AxBxC mm/in.                              | Nominal<br>Size<br>Height | Nominal<br>Size<br>Width | Nominal<br>Size<br>Depth | K<br>mm/in.  | M<br>mm/in.  | N<br>mm/in.  | O<br>mm/in.  | P<br>mm/in.  | R<br>mm/in.   | S<br>mm/in.  | Top<br>Door<br>Opening<br>Height<br>mm/in. | Top<br>Door<br>Opening<br>Width<br>mm/in. | Bottom<br>Door<br>Opening<br>Height<br>mm/in. | Bottom<br>Door<br>Opening<br>Width<br>mm/in. | Rear<br>Door<br>Opening<br>Height<br>mm/in. | Rear<br>Door<br>Opening<br>Width<br>mm/in. |
|----------------|-------------------------------------------|---------------------------|--------------------------|--------------------------|--------------|--------------|--------------|--------------|--------------|---------------|--------------|--------------------------------------------|-------------------------------------------|-----------------------------------------------|----------------------------------------------|---------------------------------------------|--------------------------------------------|
| PGLD1466CWS    | 1526 x 608 x 542<br>60.08 x 23.94 x 21.34 | 1400                      | 600                      | 600                      | 886<br>34.88 | 319<br>12.56 | 440<br>17.32 | 544<br>21.42 | 471<br>18.54 | 1288<br>50.71 | 759<br>29.88 | 406<br>16.00                               | 536<br>21.10                              | 709<br>27.91                                  | 536<br>21.10                                 | 1454<br>57.25                               | 536<br>21.10                               |
| PGLD1468CWS    | 1526 x 608 x 742<br>60.08 x 23.94 x 29.21 | 1400                      | 600                      | 800                      | 886<br>34.88 | 319<br>12.56 | 440<br>17.32 | 544<br>21.42 | 471<br>18.54 | 1288<br>50.71 | 759<br>29.88 | 406<br>16.00                               | 536<br>21.10                              | 709<br>27.91                                  | 536<br>21.10                                 | 1454<br>57.25                               | 536<br>21.10                               |
| PGLD1486CWS    | 1526 x 808 x 542<br>60.08 x 31.81 x 21.34 | 1400                      | 800                      | 600                      | 886<br>34.88 | 319<br>12.56 | 640<br>25.20 | 715<br>28.15 | 471<br>18.54 | 1288<br>50.71 | 759<br>29.88 | 406<br>16.00                               | 736<br>28.98                              | 709<br>27.91                                  | 736<br>28.98                                 | 1454<br>57.25                               | 736<br>28.98                               |
| PGLD1666CWS    | 1583 x 608 x 542<br>62.32 x 23.94 x 21.34 | 1600                      | 600                      | 600                      | 916<br>36.06 | 316<br>12.44 | 440<br>17.32 | 542<br>21.34 | 468<br>18.43 | 1331<br>52.40 | 766<br>30.16 | 436<br>17.17                               | 536<br>21.10                              | 739<br>29.09                                  | 536<br>21.10                                 | 1511<br>59.49                               | 536<br>21.10                               |
| PGLD1668CWS    | 1583 x 608 x 742<br>62.32 x 23.94 x 29.21 | 1600                      | 600                      | 800                      | 916<br>36.06 | 316<br>12.44 | 440<br>17.32 | 542<br>21.34 | 468<br>18.43 | 1331<br>52.40 | 766<br>30.16 | 436<br>17.17                               | 536<br>21.10                              | 739<br>29.09                                  | 536<br>21.10                                 | 1511<br>59.49                               | 536<br>21.10                               |
| PGLD1686CWS    | 1583 x 808 x 542<br>62.32 x 31.81 x 21.34 | 1600                      | 800                      | 600                      | 916<br>36.06 | 316<br>12.44 | 640<br>25.20 | 714<br>28.11 | 468<br>18.43 | 1331<br>52.40 | 766<br>30.16 | 436<br>17.17                               | 736<br>28.98                              | 739<br>29.09                                  | 736<br>28.98                                 | 1511<br>59.49                               | 736<br>28.98                               |
| PGLD1866CWS    | 1785 x 608 x 552<br>70.19 x 23.94 x 21.74 | 1800                      | 600                      | 600                      | 916<br>36.06 | 517<br>20.35 | 440<br>17.32 | 679<br>26.73 | 669<br>26.34 | 1431<br>56.34 | 766<br>30.16 | 637<br>25.08                               | 536<br>21.10                              | 739<br>29.09                                  | 536<br>21.10                                 | 1711<br>67.36                               | 536<br>21.10                               |
| PGLD1868CWS    | 1785 x 608 x 742<br>70.28 x 23.94 x 29.21 | 1800                      | 600                      | 800                      | 916<br>36.06 | 517<br>20.35 | 440<br>17.32 | 679<br>26.73 | 669<br>26.34 | 1431<br>56.34 | 766<br>30.16 | 637<br>25.08                               | 536<br>21.10                              | 739<br>29.09                                  | 536<br>21.10                                 | 1711<br>67.36                               | 536<br>21.10                               |
| PGLD1886CWS    | 1785 x 809 x 542<br>70.28 x 31.81 x 21.34 | 1800                      | 800                      | 600                      | 916<br>36.06 | 517<br>20.35 | 640<br>25.20 | 823<br>32.40 | 669<br>26.34 | 1431<br>56.34 | 766<br>30.16 | 637<br>25.08                               | 736<br>28.98                              | 739<br>29.09                                  | 736<br>28.98                                 | 1711<br>67.36                               | 736<br>29.98                               |

| Standard Configuration                                                                                                                                                                                             | Optional Components                                                                                                       |
|--------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------------------------------------|
| <ul style="list-style-type: none"><li>Cabinet</li><li>Keyboard compartment</li><li>Shelf (2)</li><li>Upper front window door</li><li>Lower front solid door</li><li>Rear solid door</li><li>Lifting eyes</li></ul> | <ul style="list-style-type: none"><li>Upper front solid door</li><li>Upper front solid cover</li><li>Rear Cover</li></ul> |

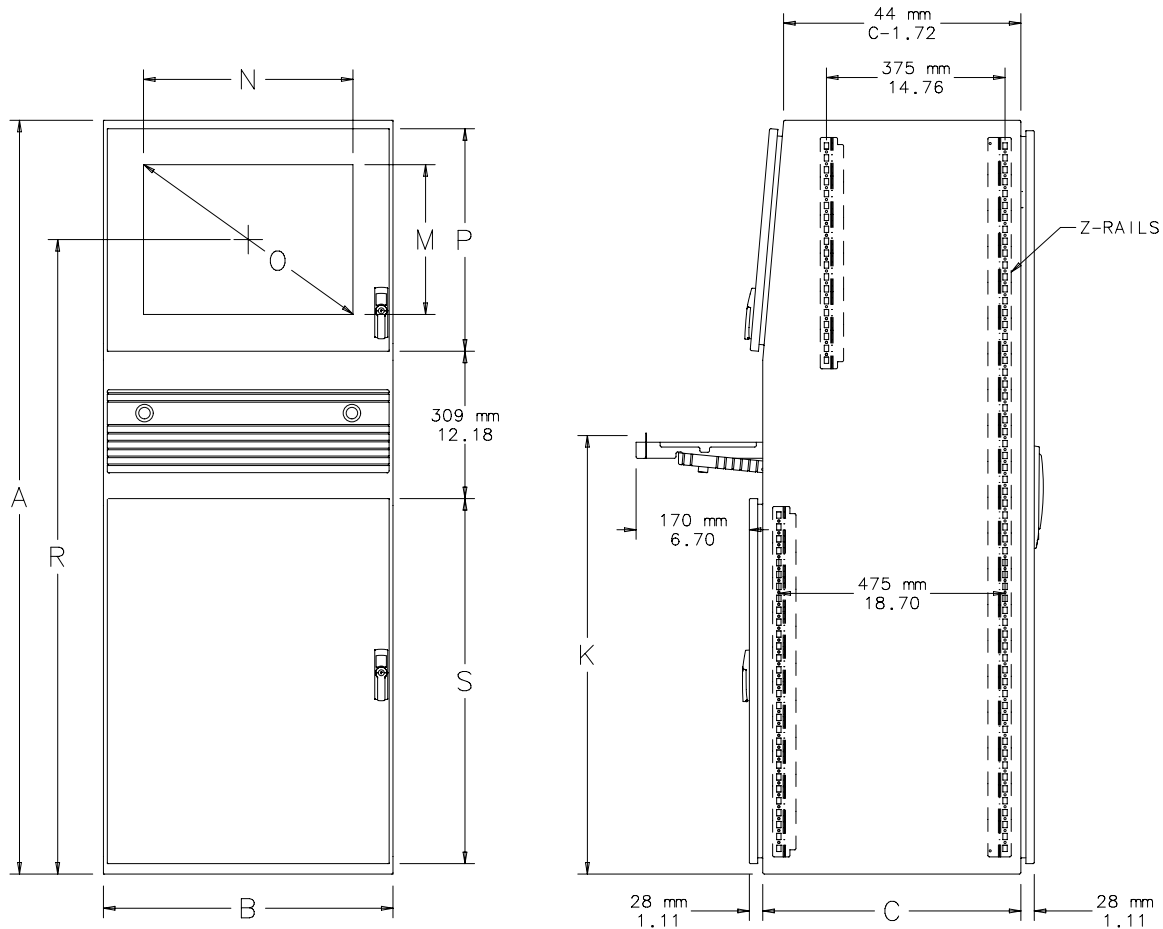
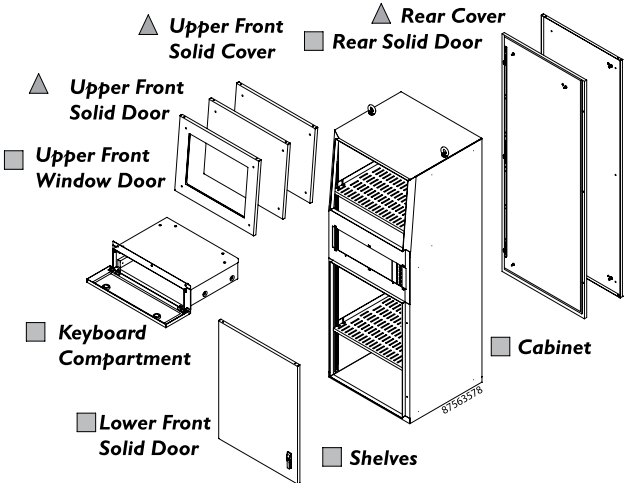


87563579

|                |                                            |  |              |              |              |        |        |        |        |        |        | Top Door | Top Door       | Bottom Door   | Bottom Door    | Rear Door     | Rear Door      |               |
|----------------|--------------------------------------------|--|--------------|--------------|--------------|--------|--------|--------|--------|--------|--------|----------|----------------|---------------|----------------|---------------|----------------|---------------|
|                |                                            |  | Nominal Size | Nominal Size | Nominal Size | K      | M      | N      | O      | P      | R      | S        | Opening Height | Opening Width | Opening Height | Opening Width | Opening Height | Opening Width |
| Catalog Number | AxBxC mm/in.                               |  | Height       | Width        | Depth        | mm/in. | mm/in. | mm/in. | mm/in. | mm/in. | mm/in. | mm/in.   | mm/in.         | mm/in.        | mm/in.         | mm/in.        | mm/in.         | mm/in.        |
| PGLD14126CWS   | 1526 x 1208 x 542<br>60.08 x 47.56 x 21.34 |  | 1400         | 1200         | 600          | 886    | 319    | 1040   | 1088   | 471    | 1288   | 759      | 406            | 1136          | 709            | 536           | 1454           | 1136          |
|                |                                            |  |              |              |              | 34.88  | 12.56  | 40.94  | 42.83  | 18.54  | 50.71  | 29.88    | 16.00          | 44.72         | 27.91          | 21.10         | 57.25          | 44.72         |

- ☐ Cabinet
- ☐ Keyboard compartment
- ☐ Keyboard compartment is on the right side and cover is on the left side
- ☐ Shelf (4)
- ☐ Upper front window door
- ☐ Lower front solid door
- ☐ Rear solid overlapping door
- ☐ Center upright
- ☐ Lifting eyes

- ▲ Upper front solid door
- ▲ Upper front solid cover
- ▲ Rear Cover

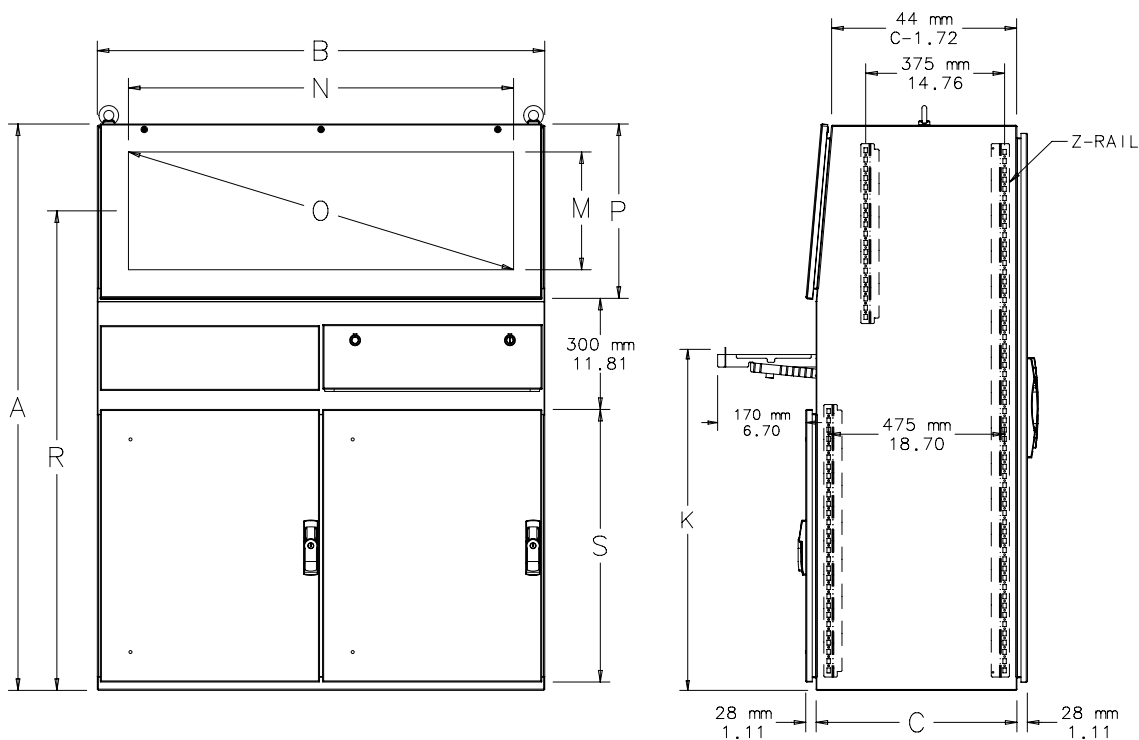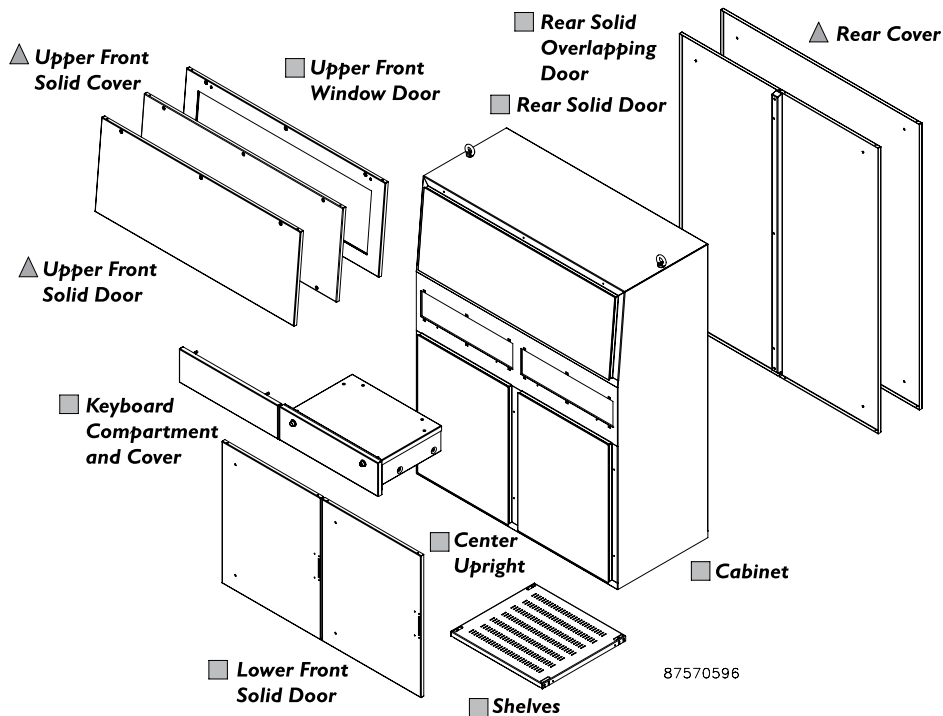


## SOLID COVERS **A-T-O**

Covers are available for upper front and rear openings. Covers mount with screws provided. Material is 16 gauge steel (14 gauge for 800-mm widths) with RAL 7035 textured light-gray polyester powder paint finish.

BULLETIN: P10, P20

| Catalog Number | Use on Opening | H (mm) | H (in.) | W (mm) | W (in.) | Fits Console A x B |
|----------------|----------------|--------|---------|--------|---------|--------------------|
| PCS46CWS       | Upper Front    | 471    | 18.54   | 592    | 23.31   | 1400 x 600         |
| PCS48CWS       | Upper Front    | 471    | 18.54   | 792    | 31.18   | 1400 x 800         |
| PCS412GLD      | Upper Front    | 471    | 18.54   | 1192   | 46.93   | 1400 x 1200        |
| PCS56CWS       | Upper Front    | 468    | 18.43   | 592    | 23.31   | 1600 x 600         |
| PCS58CWS       | Upper Front    | 468    | 18.43   | 792    | 31.18   | 1600 x 800         |
| PCS66CWS       | Upper Front    | 669    | 26.34   | 592    | 23.31   | 1800 x 600         |
| PCS68CWS       | Upper Front    | 669    | 26.34   | 792    | 31.18   | 1800 x 800         |
| PCS146GLD      | Rear           | 1482   | 58.35   | 592    | 23.31   | 1400 x 600         |
| PCS1412GLD     | Rear           | 1482   | 58.35   | 1196   | 47.10   | 1400 x 1200        |
| PCS166         | Rear           | 1539   | 60.59   | 592    | 23.31   | 1600 x 600         |
| PCS168         | Rear           | 1539   | 60.59   | 792    | 31.18   | 1600 x 800         |
| PCS186         | Rear           | 1739   | 68.46   | 592    | 23.31   | 1800 x 600         |
| PCS188         | Rear           | 1739   | 68.46   | 792    | 31.18   | 1800 x 800         |

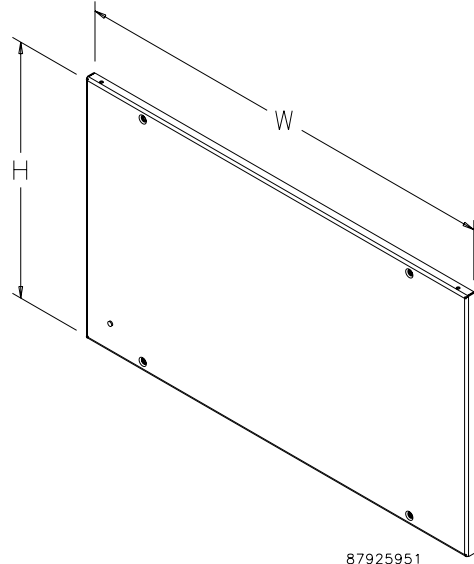


87925951

## SOLID DOORS **A-T-O**

PROLINE-style upper front doors have 140-degree hidden hinges and locking swing handle. Material is 16 gauge steel (14 gauge for 800-mm widths) with RAL 7035 textured light-gray polyester powder paint finish.

BULLETIN: P10

| Catalog Number | H x W (mm) | H x W (in.)   | Fits Console A x B |
|----------------|------------|---------------|--------------------|
| PDS46GLD       | 471 x 592  | 18.54 x 23.30 | 1400 x 600         |
| PDS48GLD       | 471 x 792  | 18.54 x 31.18 | 1400 x 800         |
| PDS412GLD      | 471 x 1192 | 18.54 x 46.93 | 1400 x 1200        |
| PDS56GLD       | 468 x 592  | 18.43 x 23.31 | 1600 x 600         |
| PDS58GLD       | 468 x 792  | 18.43 x 31.18 | 1600 x 800         |
| PDS66GLD       | 669 x 592  | 26.34 x 23.31 | 1800 x 600         |
| PDS68GLD       | 669 x 792  | 26.34 x 31.18 | 1800 x 800         |

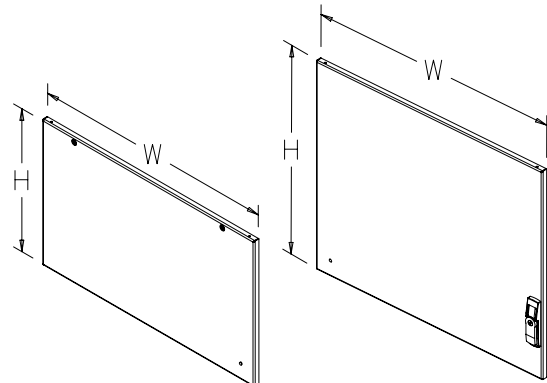

1400mm TALL 1600/1800mm TALL

87925950