




WP3

### **Specifications:**

- NEMA 4/4X, IP66-11 Rated enclosure for outdoor use.
- Lightweight molded fiberglass reinforced polyester enclosure is corrosion resistant and does not contain halogens.
- Lockable stainless steel latches.
- Integral flanges simplify wall or pole mounting.
- Applications: Power Supplies, Batteries and Auxiliary modules.
- Product weight: 7.0 lbs. (3.18 kg).
- Shipping weight: 8.3 lbs. (3.76 kg).

### **Enclosure Dimensions (H x W x D) (approximate):**

13.3" x 11.3" x 5.6" (338.1mm x 287.3mm x 142mm)

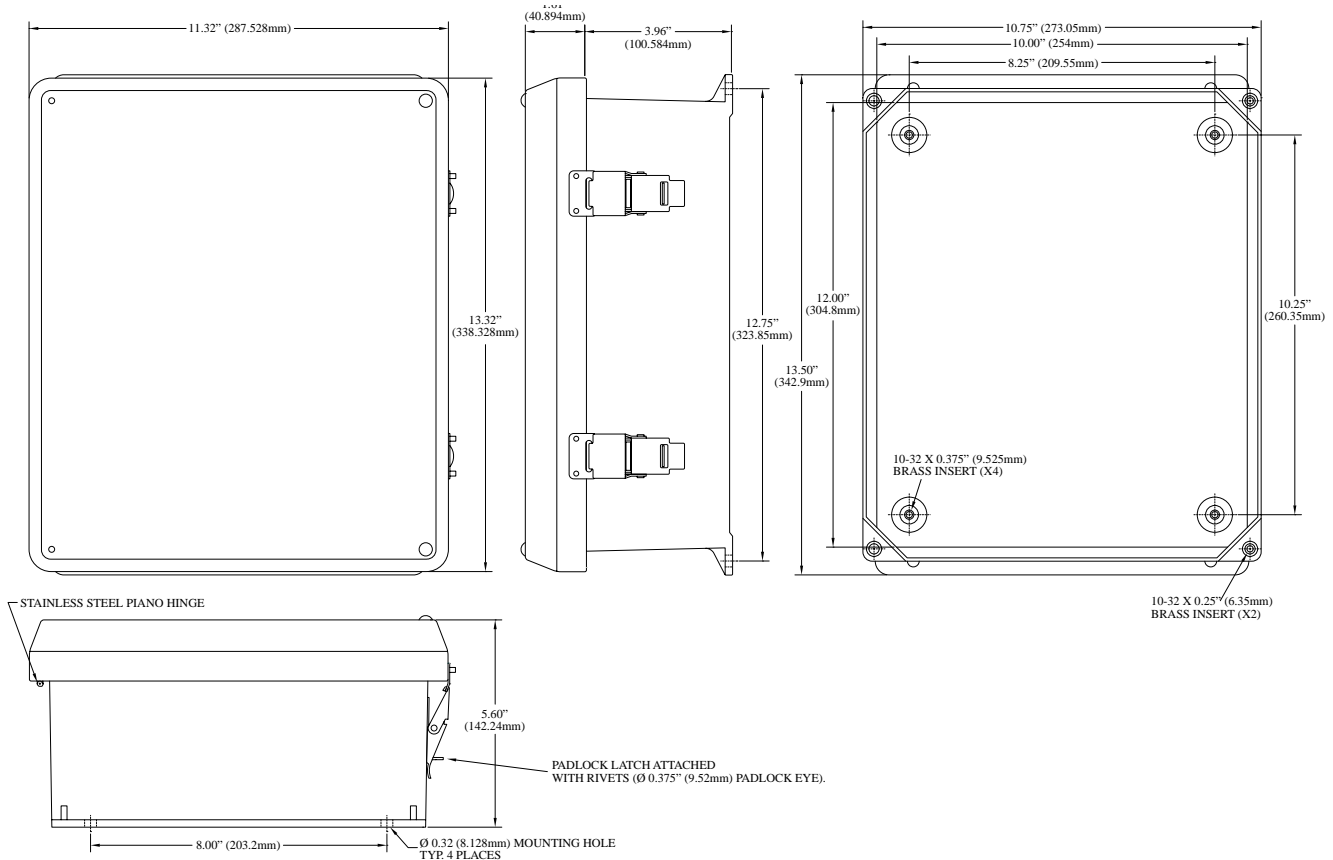

### **PMK1 Pole Mount Kit (order separately)**



PMK1

PMK1 pole mount kit is designed to simplify installation of outdoor units.

- Accommodates 2"- 8"(diameter) poles.
- Kit includes:
  - Two (2) powder coated steel mount brackets.
  - Four (4) stainless steel bolts.
  - Four (4) stainless steel lock washers.
  - Two (2) wormgear quick release straps.